


Mosaic™
Socket outlet - German standard

Cat. No(s): 2 782 13L

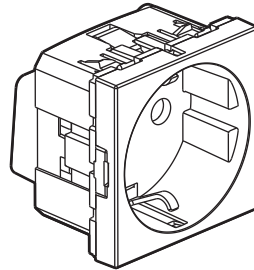

1. USE

2 P+E socket outlet with shutters, German standard.
 Can be flush-mounted or surface-mounted.
 To be fitted with finishing plates.


2. RANGE

Description	White
2 P+E socket special 4 mm ² and tapping 2 modules	2 782 13L

3. CONNECTION

Type of terminals: with screws
 Terminals capacity: 2 x 4 mm²
 Stripping length: 10 mm
 Screwdriver: flat 4 mm - PZ2

3. DIMENSIONS (mm)

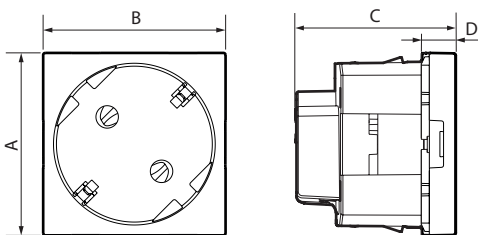

A	B	C	D
45	45	39,5	8,5

5. TECHNICAL CHARACTERISTICS

■ **5.1 Mechanical characteristics**

Impact resistance: IK 04
 Penetration against solid bodies and liquids: IP 20

■ **5.2 Material characteristics**

Base: PC
 Cover plate: White PC RAL 9003

Halogen-free
 UV-resistant

Self-extinguishing:
 850°C/30 s for insulating components
 650°C/30 s for the other insulating part

■ **5.3 Electrical characteristics**

Voltage: 250 V~
 Current: 16 A

■ **5.4 Climate characteristics**

Storage temperature: -10°C to +70°C
 Usage temperature: -5°C to +35°C

6. CLEANING

Clean the surface with a cloth.
 Do not use acetone, tar-removing cleaning agents or trichloroethylene.
 Resistant to the following products:
 Hexane, methylated spirit, soapy water, diluted ammonia, bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.
 Anios, Surfanios, Bactylisine, diluted hydrogen peroxide (35%).

Caution: Always test before using other special cleaning products.

8. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.
 See e-catalogue.