



## Arteor™ with Netatmo - British Standard Connected switch without neutral with dimmer option

Cat. Nos: 5 746 37/38/39/40

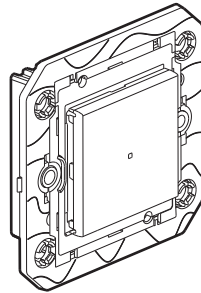

5 746 37

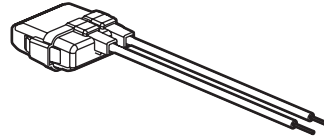

0 401 49


### 1. USE

Connected switch without neutral with dimmer option, configured by default as ON/OFF (dimmer mode can be activated from the Home + Control app). Can be combined with one or more wireless lighting controls. For local or remote control of your lighting. Supplied with an active power bleeder (Cat. No. 0 401 49), mandatory to ensure optimum operation with commercially-available lamps. One bleeder per lighting circuit is sufficient. Easy to install in place of a standard switch in a box 25 mm deep (minimum).

### 2. RANGE

Description	White	Magnesium	Soft Alu	Champagne
Product for use in conjunction with the starter pack (5 746 01/02/03/04). With LED indicator (locator) and RESET button (hidden) used to return to factory settings. Mechanism supplied with rocker plate and support frame.	5 746 37	5 746 38	5 746 39	5 746 40

### 3. DIMENSIONS (mm)

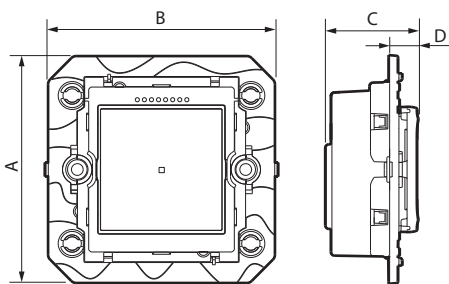


A	B	C	D
81.5	81.5	33	10.5

### 4. CONNECTION

Terminal type: with screws  
 Terminal capacity: 2 x 1.5 mm<sup>2</sup> - 2 x 2.5 mm<sup>2</sup> - 1 x 4 mm<sup>2</sup>  
 Stripping length: 8 mm

### 5. OPERATION

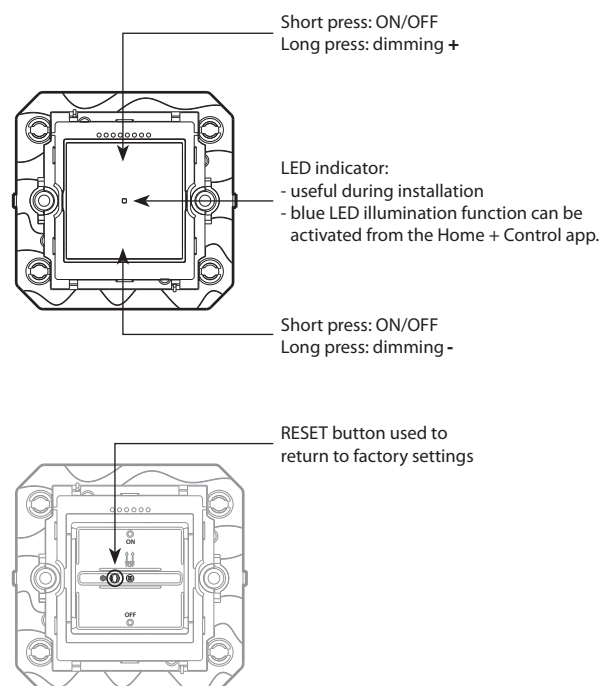

## 6. TECHNICAL CHARACTERISTICS

### ■ 6.1 Mechanical characteristics

Protection against impacts: IK 04

Protection against solid bodies/liquids: IP 20

### ■ 6.2 Material characteristics

Rocker plate: ABS

Mechanism casing: PC

Halogen-free

UV-resistant

Self-extinguishing:

850°C/30 s for insulating parts holding live parts in place.

650°C/30 s for other insulating components.

### ■ 6.3 Electrical characteristics

Voltage: 110-240 V~

Frequency: 50/60 Hz

Power: 300 W

Standby consumption: 0.3 mA

### Zigbee technology

Frequency bands: 2.4 GHz to 2.4835 GHz

Power level: < 100 mW

Range: 200 m of unobstructed space

10 m between products indoors

### ■ 6.4 Climate characteristics

Usage temperature: + 5°C to + 35°C

Storage temperature: 0°C to + 45°C

## 7. CARE

Clean the surface with a cloth.

Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Resistant to the following products:

Hexane, methylated spirit, soapy water, diluted ammonia, pure bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

**Caution:** Always test before using special cleaning products.

## 8. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.

See e-catalogue.

The undersigned, LEGRAND, declares that the radio-electric equipment type (5 746 37/38/39/40) complies with directive 2014/53/EU.

The full text of the EU declaration of conformity is available on the following website: [www.legrandoc.com](http://www.legrandoc.com)