


Suno™ IP44 plates

Cat. No(s): 7 211 44, 7 212 44
 7 213 44, 7 214 44

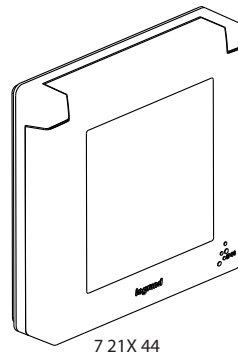

7 21X 44


1. USE

Frame plates white color supplied with translucent cover for fitting on SUNO mechanisms.

2. RANGE

1 Gang IP44	White	7 211 44
	Ivory	7 212 44
	Grey	7 213 44
	Black	7 214 44

3. DIMENSIONS (mm)

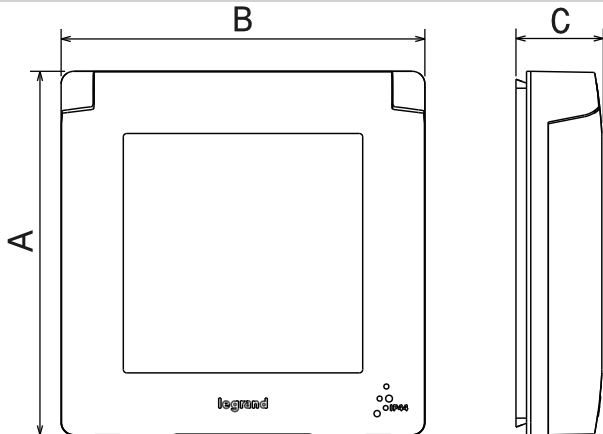

References	A	B	C
7 21X 44	86	86	20,3

4. MOUNTING

The plates snap onto the socket adapter or the switch cover. In case of the sockets, the socket cover clamp the frame.

5. TECHNICAL DATA

- 5.1 Mechanical characteristics
 180° opening capacity of the cover
 Impact tests: IK 04
 Penetration against solid bodies and liquids: IP 44

■ 5.2 Material characteristics

- Plates: ABS
- Under-plates: PC
- UV resistant
- Halogen free
- Self-extinguishing: 650° C / 30 s

■ 5.3 Climatical characteristics

- Storage temperature: - 10° C to + 70° C
- Use temperature: - 5° C to + 50° C

6. CLEANING

Surface cleaning with a cloth. Do not use: acetone, tar remover, trichloroethylene.

■ 6.1 Resistance to the following cleaning substances

- Hexane (EN 60669-1),
- Methylated spirit,
- Soapy water,
- Diluted ammonia,
- Diluted pure bleach 10%,
- Glass cleaning product,
- Pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

7. SPECIAL USE

The plates must not be painted.