


**Mallia™ Senses with Netatmo**  
**Wireless 4 scenes control**

Cat. No(s): **2 815 15DS - 2 815 15MB**  
**2 815 15MW**

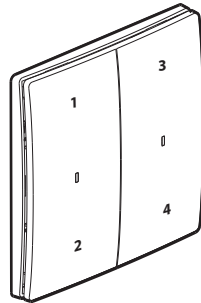


**1. USE**

Allows control of all connected wired controls (lights, appliances, curtains/roller shutters).  
 Requires the prior installation of a starter pack for connected installation or a Control module "with Netatmo".  
 Fixes directly on the wall or screws onto a flush-mounting box. Multi-gang versions can be combined with other wiring accessories.  
 Fits on a furniture (movable).

**2. RANGE**



Description	Silver	Black	White
Wireless control connected, 4 configurable scenarios. Complete delivered with a battery and protection film. Equipped with an LED indicator (configuration) and a RESET button (hidden) used to return to factory settings. Supplied with repositionable self-adhesive fixings.	2 815 15DS	2 815 15MB	2 815 15MW

**3. DIMENSIONS (mm)**

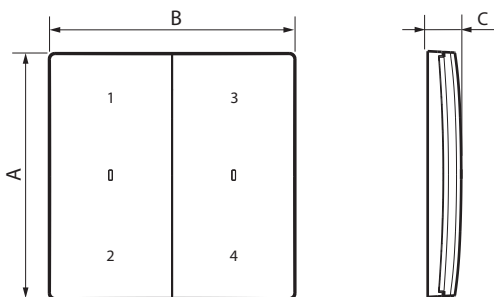

A	B	C
86	86	12

**4. OPERATION**

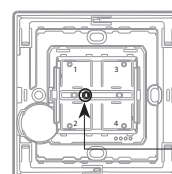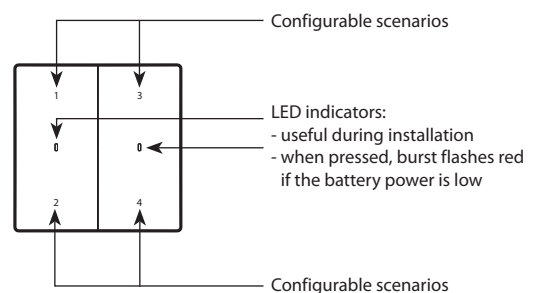

RESET button used to return to factory mode

## 5. TECHNICAL CHARACTERISTICS

### ■ 5.1 Mechanical characteristics

Protection against impacts: IK 02

Protection against solid bodies and/or liquids: IP 20

### ■ 5.2 Material characteristics

Cover plate: PC

Mechanism casing with grid: Fibreglass-reinforced (10%) PC

Halogen-free

UV-resistant

Self-extinguishing: 650°C/30 s

### ■ 5.3 Electrical characteristics

Powered by a CR2032 - 3 V lithium battery (supplied)

Battery life: 8 years for 10 activations a day

Frequency bands: 2.4 GHz to 2.4835 GHz

Power level: < 100 mW

### ■ 5.4 Climate characteristics

Usage temperature: +5°C to + 35°C

Storage temperature: 0°C to + 45°C

## 6. CARE

Clean the surface with a cloth.

Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Resistant to the following products:

Hexane, methylated spirit, soapy water, diluted ammonia, bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

**Caution:** Always test before using special cleaning products.

Do not paint the cover plate.



Take care to recycle the battery appropriately.

## 7. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.

See e.catalogue.

The undersigned, LEGRAND, declares that the radio-electric equipment type (2 815 15DS/MB/MW) complies with directive 2014/53/EU.

The full text of the EU declaration of conformity is available on the following website: [www.legrandoc.com](http://www.legrandoc.com)