



# Eloe™ Senses Access


Cat. No(s): 6 180 17/28/34/37/39

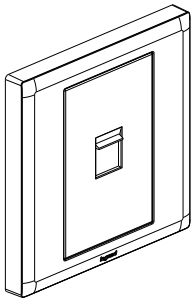


6 180 17

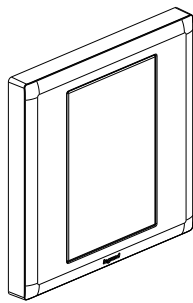


6 180 28

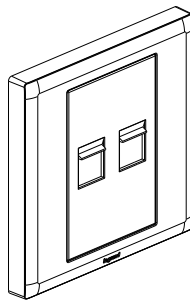

6 180 34

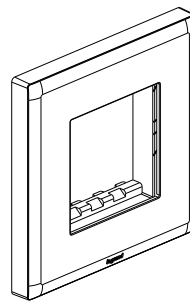

6 180 37

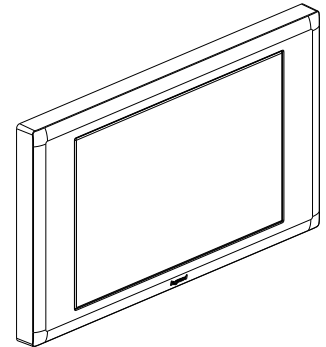

6 180 39


## 1. USE

Decoration and reserve for future use.  
 (Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.)

## 2. RANGE

Designation	White
1 GANG ADAPTATOR 1 X KEYSTONE	6 180 17
1 GANG BLANKING PLATE	6 180 28
1 GANG ADAPTATOR 2 X KEYSTONE	6 180 34
1 GANG ADAPTOR ARTEOR 2 MODULES	6 180 37
2 GANG BLANKING PLATE	6 180 39

## 3. DIMENSIONS (mm)

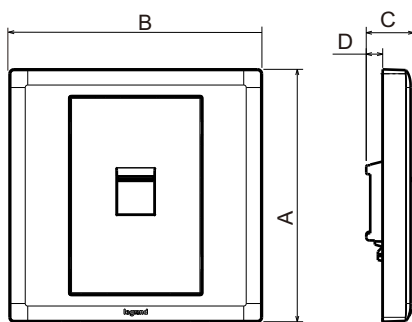

References	A	B	C	D
6 180 17/34	86	86	16.2	5.6
6 180 28	86	86	9.5	0
6 180 37	86	86	15	5.5
6 180 39	86	146	9.5	0

## 4. TECHNICAL CHARACTERISTICS

### 4.1 Material characteristics

Plate: PC  
 Frame: PC  
 Other: PC  
 Self-extinguishing:  
 + 650° C / 30 s

### 4.2 Climatic characteristics

Storage temperatures: -10°C to +70°C  
 Operating temperatures: -5°C to +35°C

### 4.3 Mechanical characteristics

Impact test: IK04  
 Protection against solids & liquids: IP20

## 5. CLEANING

Surface cleaning with a soft, slightly damp cloth.  
 Do not use: acetone, tar remover, trichloroethylene

## 6. CONFORMITY - APPROVALS

Comply with installation and manufacturing standards.  
 Refer to e-catalogue.  
 Conform to IEC 60670-1