


Eloe™ Senses 45A cooker control unit

Cat. No(s): 6 180 78

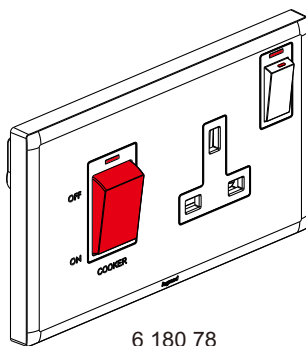

6 180 78


1. USE

High capacity double pole switches for the control of fixed appliances eg. cooker ovens units, and 13A BS switched socket, available with LED "power on" indicator.
 (Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.)

2. RANGE

Designation	White
2 GANG COOKER UNIT (45A DP SWITCH + 13A BS + NEON)	6 180 78

3. DIMENSIONS (mm)

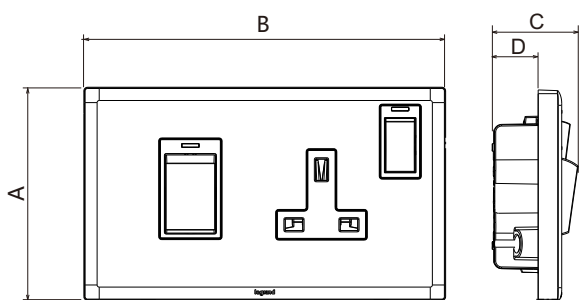

References	A	B	C	D
6 180 78	86	146	35	18.5

Box depth ≥ 40 mm

4. CONNECTION

Types of terminals: with screws
 Terminal capacity: 2 × 6 mm²
 1 × 10 mm²
 Recommended stripping length: 24mm / 8mm
 Recommended screwdriver size: <4 mm flat blade

5. TECHNICAL CHARACTERISTICS

5.1 Material characteristics

Rocker: PC
 Plate: PC
 Frame: PC
 Base: PP
 Self-extinguishing:
 + 850° C / 30 s for insulating parts holding live parts in place
 + 650° C / 30 s for other parts made of insulating materials

5.2 Electrical characteristics

Voltage: 250V~
 Current: 45A/13A

5.3 Climatic characteristics

Storage temperatures: -10°C to +70°C
 Operating temperatures: -5°C to +35°C

5.4 Mechanical characteristics

Impact test: IK04
 Protection against solids & liquids: IP20

6. CLEANING

Surface cleaning with a soft, slightly damp cloth.
 Do not use: acetone, tar remover, trichloroethylene

7. CONFORMITY - APPROVALS

Conform to BS 4177.