



Eloe™ Senses EURO/US Socket


Cat. No(s): 6 180 62/64/90

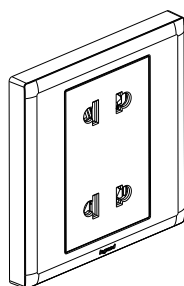

6 180 62

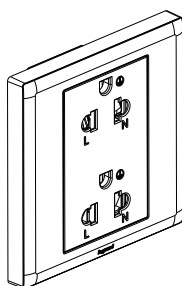

6 180 64

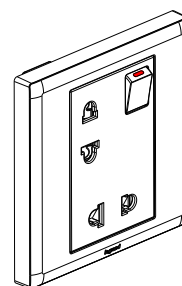

6 180 90


1. USE

One gang 2X2P EURO/US socket outlets designed for 15A/16A plug.
 (Supplied with M3.5 screws for BS boxes. Flush mounting or surface mounting.)

2. RANGE

Designation	White
1 GANG 2X2P EURO-US SOCKET	6 180 62
1 GANG 2X2P+E EURO/US SOCKET	6 180 64
1 GANG 2P EURO-US SOCKET + 1WAY SWITCH	6 180 90

3. DIMENSIONS (mm)

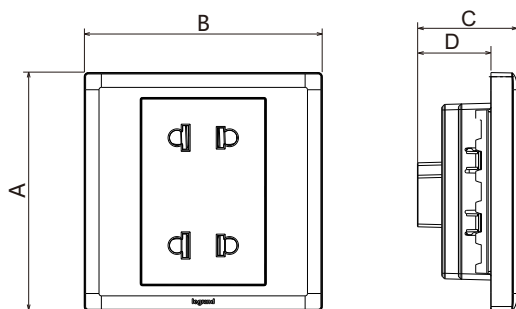

References	A	B	C	D
6 180 62	86	86	36.1	26.6
6 180 64	86	86	36.2	26.7
6 180 90	86	86	36.2	22.5

Box depth ≥ 35 mm

4. CONNECTION

Type of Terminals : plaquette terminal

Terminal capacity: 2 × 2.5 mm²

2 × 4 mm²

2 × 6 mm²

Recommended screwdriver size: <4 mm flat blade

Recommended stripping length: 8 mm

Recommended terminal tightening torque: 0.5Nm

5. TECHNICAL CHARACTERISTICS

5.1 Material characteristics

Rocker: PC

Plate: PC

Frame: PC

Base: PC

Self-extinguishing:

+ 850° C / 30 s for insulating parts holding live parts in place

+ 650° C / 30 s for other parts made of insulating materials

5.2 Electrical characteristics

US socket:

Voltage: 127V~ Current: 15A

EURO socket:

Voltage: 250V~ Current: 16A

5.3 Climatic characteristics

Storage temperatures: -10°C to +70°C

Operating temperatures: -5°C to +35°C

5.4 Mechanical characteristics

Impact test: IK04

Protection against solids & liquids: IP20

6. CLEANING

Surface cleaning with a soft, slightly damp cloth.

Do not use: acetone, tar remover, trichloroethylene

7. CONFORMITY - APPROVALS

Compliance with installation and manufacturing standards.

Refer to e-catalogue.