


## Eloe™ Senses Fan Control

Cat. No(s): 6 180 96

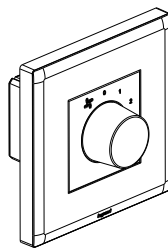

6 180 96


### 1. USE

5 speed Fan Control.  
 (Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.)

### 2. RANGE

Designation	White
1 GANG FAN CONTROL 5 SPEEDS	6 180 96

### 3. DIMENSIONS (mm)

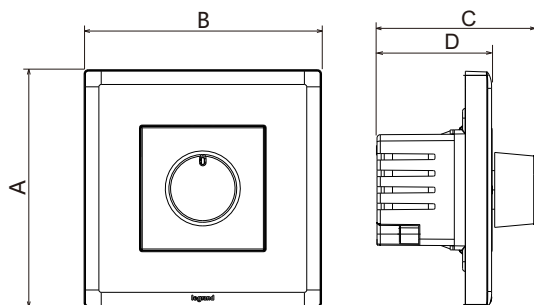

References	A	B	C	D
6 180 96	86	86	57.7	32.2

Minimum depth of the box > 35 mm

### 4. CONNECTION

#### 4.1 Terminal

Types of terminals: with screws  
 Terminal capacity: 4 × 1 mm<sup>2</sup>  
 3 × 1.5 mm<sup>2</sup>  
 2 × 2.5 mm<sup>2</sup>  
 1 × 4 mm<sup>2</sup>

Recommended stripping length: 8 mm  
 Recommended screwdriver size: 4 mm flat blade

### 5. TECHNICAL CHARACTERISTICS

#### 5.1 Material characteristics

Button: PC  
 Plate: PC  
 Frame: PC  
 Base: PC  
 Self-extinguishing:  
 + 850°C / 30 s for insulating parts holding live parts in place  
 + 650°C / 30 s for other parts made of insulating materials

#### 5.2 Electrical characteristics

Voltage: 200 - 240V~  
 Frequency: 50/60Hz  
 Min:40VA Max:400VA

#### 5.3 Climatic characteristics

Storage temperatures: -10°C to +70°C  
 Operating temperatures: -5°C to +35°C

#### 5.4 Mechanical characteristics

Impact test: IK04  
 Protection against solids & liquids: IP20

### 6. CLEANING

Surface cleaning with a soft, slightly damp cloth.  
 Do not use: acetone, tar remover, trichloroethylene.

### 7. CONFORMITY - APPROVALS

Conform to BS EN 60669-2-1.