


Eloe™ Senses Keycard switch

Cat. No(s): 6 180 12

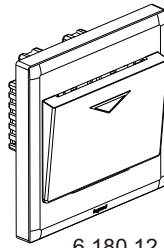

6 180 12


1. USE

Hotel room power control, 30S power off delay.
 (Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.)

2. RANGE

Designation	White
1GANG KEY CARD SWITCH	6 180 12

3. DIMENSIONS (mm)

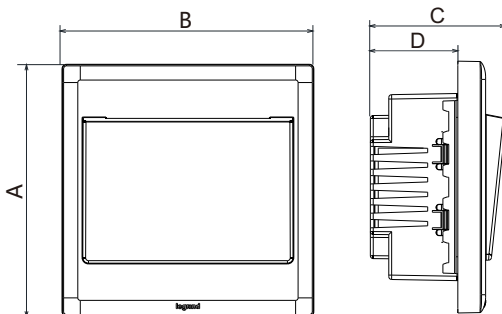

References	A	B	C	D
6 180 12	86	86	46.4	29.9

Minimum depth of the box > 35 mm

4. CONNECTION

4.1 Terminal

Types of terminals: with screws

Terminal capacity: 4 × 1 mm²
 4 × 1.5 mm²
 3 × 2.5 mm²
 2 × 4 mm²
 1 × 6 mm²

Recommended stripping length: 12 mm

Recommended screwdriver size: 4 mm flat blade

5. TECHNICAL CHARACTERISTICS

5.1 Material characteristics

Plate: PC
 Frame: Steel
 Base: PC
 Self-extinguishing:
 + 850°C / 30 s for insulating parts holding live parts in place
 + 650°C / 30 s for other parts made of insulating materials

5.2 Electrical characteristics

Voltage: 200-240V ~ 50/60Hz
 Current: 16A

5.3 Climatic characteristics

Storage temperatures: -10°C to +70°C
 Operating temperatures: -5°C to +35°C

5.4 Mechanical characteristics

Impact test: IK04
 Protection against solids & liquids: IP20

6. CLEANING

Surface cleaning with a soft, slightly damp cloth.
 Do not use: acetone, tar remover, trichloroethylene.

7. CONFORMITY - APPROVALS

Conform to BS EN 60669-2-1.