



# Eloe™ Senses RJ11 socket

Cat. No(s): 6 180 95/97

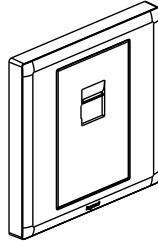

6 180 95

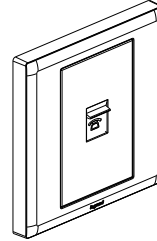

6 180 97


## 1. USE

Telephone socket outlet with shutters for the transmission telephone signals.  
 (Supplied with M3.5 screws for BS boxes. Flush mounting or Surface mounting.)

## 2. RANGE

Designation	White
1 GANG BS MASTER TELEPHONE SOCKET	6 180 95
1 GANG RJ11 SOCKET	6 180 97

## 3. DIMENSIONS (mm)

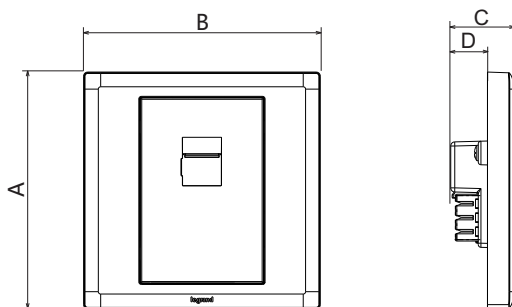

References	A	B	C	D
6 180 95	86	86	23.4	13.35
6 180 97	86	86	31.9	20.4

Box depth ≥ 40 mm

## 4. TECHNICAL CHARACTERISTICS

### 4.1 Material characteristics

Shutter: PC  
 Plate: PC  
 Frame: PC  
 Self-extinguishing:  
 + 850° C / 30 s for insulating parts holding live parts in place  
 + 650° C / 30 s for other parts made of insulating materials

### 4.2 Electrical characteristic

-Contact blades gold plated on nickel(gold thickness: 0.125µm)

### 4.3 Climatic characteristics

Storage temperatures: -10°C to +70°C  
 Operating temperatures: -5°C to +35°C

### 4.4 Mechanical characteristics

Impact test: IK04  
 Protection against liquids: IP20

## 5. CLEANING

Surface cleaning with a soft, slightly damp cloth.  
 Do not use: acetone, tar remover, trichloroethylene