



Eloe™ Senses

RJ45 SOCKET

Cat. No(s): 6 180 91/92/93

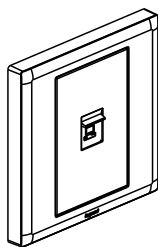

6 180 91/93

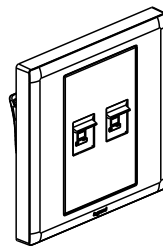

6 180 92


1. USE

Computer socket outlet for the transmission of data. With shutters.
 (Supplied with M3.5 screws for BS boxes. Flush mounting or surface mounting.)

2. RANGE

Designation	White
1 GANG RJ45 CAT6 UTP	6 180 91
1 GANG DOUBLE RJ45 CAT6 UTP	6 180 92
1 GANG RJ45 CAT.5 UTP	6 180 93

3. DIMENSIONS (mm)

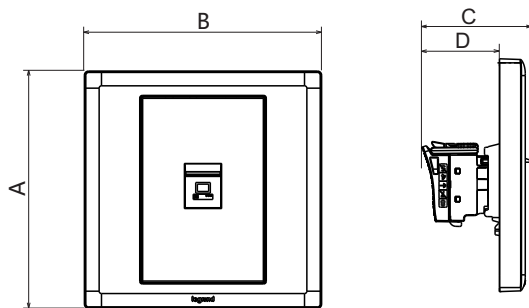

References	A	B	C	D
6 180 91/93	86	86	40.1	28.6
6 180 92	86	86	31.9	20.4

Minimum depth of the box > 40 mm

4. TECHNICAL CHARACTERISTICS

4.1 Material characteristics

Shutter: PC
 Plate: PC
 Frame: PC
 Base: PC
 Self-extinguishing:
 + 850° C / 30 s for insulating parts holding live parts in place
 + 650° C / 30 s for other parts made of insulating materials

4.2 Electrical characteristics

-Breakdown Voltage $\geq 1000V$
 -Contact resistance $\leq 20m\Omega$
 -Insulation resistance $\geq 500m\Omega$ at DC 100V
 -Contact blades gold plated on nickel (gold thickness: 0.75 μm)

4.3 Climatic characteristics

Storage temperatures: -10°C to +70°C
 Operating temperatures: -5°C to +35°C

4.4 Mechanical characteristics

Impact test: IK04
 Protection against solids & liquids: IP20

5. CLEANING

Surface cleaning with a soft, slightly damp cloth.
 Do not use: acetone, tar remover, trichloroethylene.