


Arteor™ RSA Socket

Cat. No(s): 5 721 36/48 - 5 726 36/48 - 5 724 68

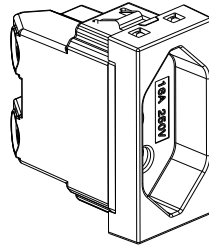

5 721 36
 5 726 36
 5 726 48
 5 721 48
 5 724 68


1. USE

New and current South African standard sockets.
 (Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.)

2. RANGE

Designation	White ○	Magnesium ●	Champagne ●	Soft Alu ●	Red ●
2P+E 1M NEW RSA SOCKET	5 721 36	5 726 36	5 726 48	5 721 48	5 724 68

3. DIMENSIONS (mm)

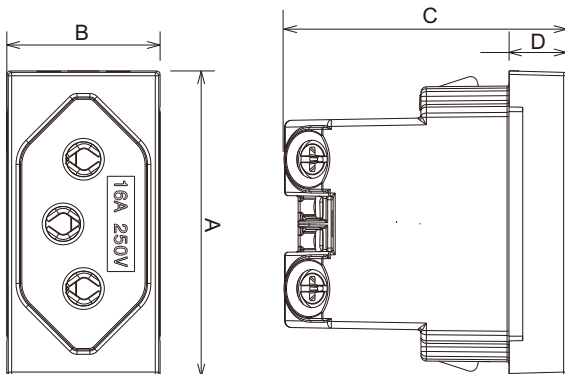

References	A	B	C	D
5 721 36/48 - 5 726 36/48 - 5 724 68	44.95	22.5	41.5	8.5

4. CONNECTION

Types of terminals: with screws
 Terminal capacity: 3 × 1 mm²
 3 × 1.5 mm²
 2 × 1.5 mm²
 1 × 4 mm²
 Recommended stripping length: 12 mm
 Recommended screwdriver size: <4 mm flat blade

5. TECHNICAL CHARACTERISTICS

5.1 Material characteristics

Base: PC
 Cover plates: PC
 Self-extinguishing:
 + 850° C / 30 s for insulating parts holding live parts in place
 + 650° C / 30 s for other parts made of insulating materials

5.2 Electrical characteristics

Voltage: 250V~
 Current: 16A

5.4 Climatic characteristics

Storage temperatures: -10°C to +70°C
 Operating temperatures: -5°C to +50°C

5.5 Mechanical characteristics

Impact test: IK04
 Protection against solids & liquids: IP20

6. CLEANING

Surface cleaning with a soft, slightly damp cloth.
 Do not use: acetone, tar remover, trichloroethylene

7. CONFORMITY - APPROVALS

Conform to SANS 164-2.