


Belanko™ S

Multistandard + EURO-US switched socket

Cat. No(s): 6 176 61

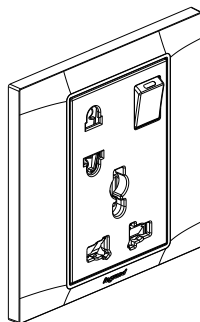

6 176 61


1. USE

One gang multistandard and EURO-US switched socket.
 (Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.)

2. RANGE

Designation	White
1Gang Multistandard and EURO US Switched Socket	6 176 61

3. DIMENSIONS (mm)

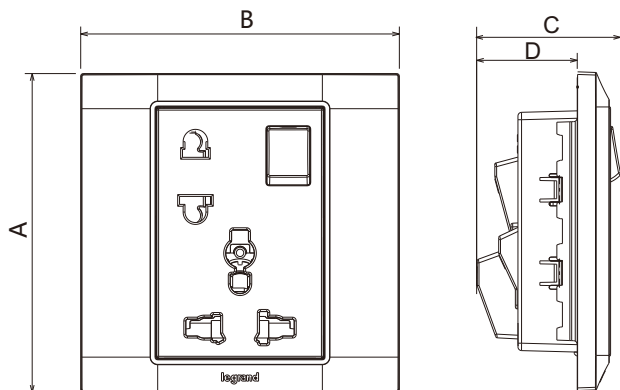

References	A	B	C	D
6 176 61	86	86	38.7	27.15

Recommended box depth \geq 35 mm

4. CONNECTION

Types of terminals: with screws

Terminal capacity: $3 \times 1 \text{ mm}^2$
 $3 \times 1.5 \text{ mm}^2$
 $2 \times 2.5 \text{ mm}^2$
 $1 \times 4 \text{ mm}^2$

Recommended stripping length: 12 mm

Recommended screwdriver size: <4 mm flat blade

5. TECHNICAL CHARACTERISTICS

5.1 Material characteristics

Rocker: PC
 Plate: PC
 Frame: PC
 Base: PC
 Self-extinguishing:
 + 850° C / 30 s for insulating parts holding live parts in place
 + 650° C / 30 s for other parts made of insulating materials

5.2 Electrical characteristics

EURO-US Socket:
 Voltage: 250V~ Current: 16A

Multistandard Socket:
 Voltage: 127V~ Current: 15A
 Voltage: 250V~ Current: 2.5/5/6/10/13/16A
 Frequency: 50/60Hz

5.3 Climatic characteristics

Storage temperatures: -10°C to +70°C
 Operating temperatures: -5°C to +35°C

5.4 Mechanical characteristics

Impact test: IK04
 Protection against solids & liquids: IP20

6. CLEANING

Surface cleaning with a soft, slightly damp cloth.
 Do not use: acetone, tar remover, trichloroethylene

7. CONFORMITY - APPROVALS

Conform with installation and manufacturing standards.
 Refer to e-catalogue.