



Céliane™ Decorative plates

Cat. No(s): CP0001/02/03/04/06/07/08/09/10/11/13/21/22/23/24
 CP0201/02/03/04/09/10/13 - CP0301/02/03/04/06/07/08/11/21/22/23/24
 CP0401/02/03/04/06/07/08/11/21/22/23/24 - CP0501/02/03/04/06/07/08/11/21/22/23/24

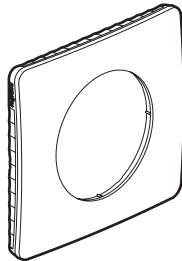

CP0001

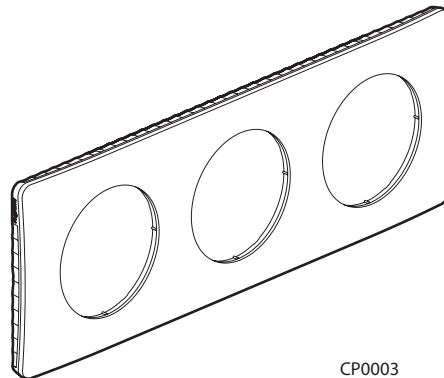

CP0003

1. USAGE

Faceplates for 1-gang to 3-gang wiring accessories.
 Horizontal or vertical mounting.


2. RANGE

1-gang plates




Enameled white	CP0001	CP0021
Enameled ivory	CP0201	-
Oven blue	CP0301	CP0321
Saffron Yellow	CP0401	CP0421
Celadon Green	CP0501	CP0521

 2-gang plates - Center distance 71 mm




Enameled white	CP0002	CP0022
Enameled ivory	CP0202	-
Oven blue	CP0302	CP0322
Saffron Yellow	CP0402	CP0422
Celadon Green	CP0502	CP0522

 3-gang plates - Center distance 71 mm



Enameled white	CP0003	CP0023
Enameled ivory	CP0203	-
Oven blue	CP0303	CP0323
Saffron Yellow	CP0403	CP0423
Celadon Green	CP0503	CP0523

4-gang plates - Center distance 71 mm

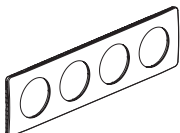

Enameled white	CP0004	CP0024
Enameled ivory	CP0204	-
Oven blue	CP0304	CP0324
Saffron Yellow	CP0404	CP0424
Celadon Green	CP0504	CP0524


2. RANGE (continued)

2-gang plates - Center distance 57 mm




Enameled white	CP0006
Oven blue	CP0306
Saffron Yellow	CP0406
Celadon Green	CP0506

3-gang plates - Center distance 57 mm

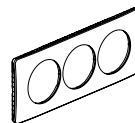


Enameled white	CP0007
Oven blue	CP0307
Saffron Yellow	CP0407
Celadon Green	CP0507

 Extended 2-station plates (4/5 modules)



Enameled white	CP0008
Oven blue	CP0308
Saffron Yellow	CP0408
Celadon Green	CP0508

Extended 3-station plates (6/8 modules)

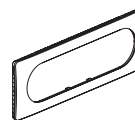

Enameled white	CP0011
Oven blue	CP0311
Saffron Yellow	CP0411
Celadon Green	CP0511


1 module plates



Enameled white	CP0013
Enameled ivory	CP0213

2. RANGE (continued)


2 x 2-gang plates

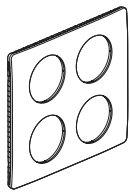

Enameled white
Enameled ivory

CP0009
CP0209


2 x 3-gang plates

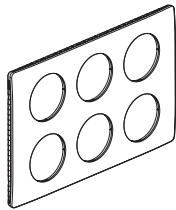

Enameled white
Enameled ivory

CP0010
CP0210

3. DIMENSIONS (mm)

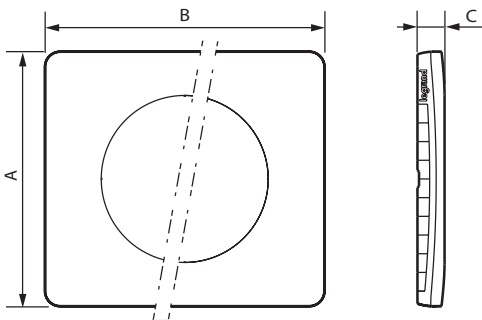

References	A	B	C
CP0001/021/201/301/321/401/421/501/521	82	90	9
CP0002/022/202/302/322/402/422/502/522	82	161	9
CP0003/023/203/303/323/403/423/503/523 CP0011/311/411/511	82	232	9
CP0004/024/204/304/324/404/424/504/524	82	303	9
CP0006/306/406/506	82	147	9
CP0007/307/407/507	82	204	9
CP0008/308/408/508	82	161	9
CP0009/209	159	175	9
CP0010/210	159	246	9
CP0013/213	82	41.5	9

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Protection against impacts: IK 04

■ 4.2 Material characteristics

Plate: Painted PC + varnish (polyglass appearance)

Underplate: satin ABS

Halogen-free

Self-extinguishing: 650°C/30 s

■ 4.3 Climate characteristics

Storage temperature: - 10°C to +70°C

Usage temperature: - 5°C to +50°C

5. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following products:

Hexane, methylated spirit, soapy water, window-cleaning products.

No paint should be applied to the plates.

Caution: Always test before using other special cleaning products

6. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.

See e-catalogue.