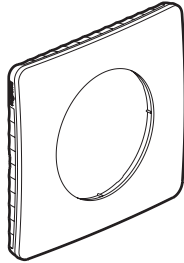
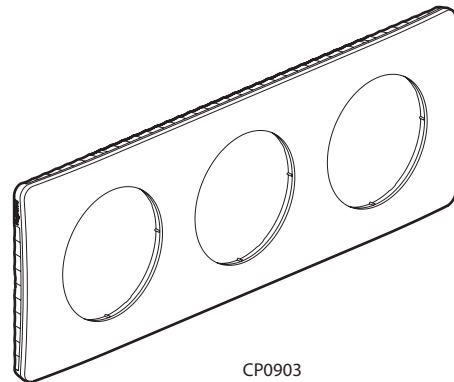


Céliane™
Decorative plates - matte finish

Cat. No(s): CP0101/02/03/04/06/07/08/09/10/11/13/21/22/23/24
 CP0901/02/03/04/06/07/08/11/21/22/23/24
 CP1001/02/03/04/06/07/08/11/21/22/23/24
 CP1101/02/03/04/06/07/08/11/21/22/23/24



CP0901




CP0903

1. USE

 
Faceplates for 1-gang to 6-gang wiring accessories.
 Horizontal or vertical mounting.
 Indoor use only.

2. RANGE

 
1-gang plates

	Matte Black Storm blue Ash grey Almond white	CP0101 CP0901 CP1001 CP1101	CP0121 CP0921 CP1021 CP1121
---	---	--------------------------------------	--------------------------------------

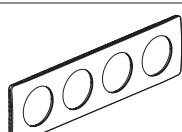
2-gang plates - Center distance 71 mm

	Matte Black Storm blue Ash grey Almond white	CP0102 CP0902 CP1002 CP1102	CP0122 CP0922 CP1022 CP1122
---	---	--------------------------------------	--------------------------------------

 
3-gang plates - Center distance 71 mm

	Matte Black Storm blue Ash grey Almond white	CP0103 CP0903 CP1003 CP1103	CP0123 CP0923 CP1023 CP1123
---	---	--------------------------------------	--------------------------------------

 
4-gang plates - Center distance 71 mm

	Matte Black Storm blue Ash grey Almond white	CP0104 CP0904 CP1004 CP1104	CP0124 CP0924 CP1024 CP1124
---	---	--------------------------------------	--------------------------------------

2-gang plates - Center distance 57 mm

 
	Matte Black Storm blue Ash grey Almond white	CP0106 CP0906 CP1006 CP1106	
---	---	--------------------------------------	--

3-gang plates - Center distance 57 mm

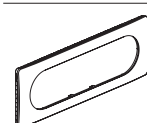
	Matte Black Storm blue Ash grey Almond white	CP0107 CP0907 CP1007 CP1107	
---	---	--------------------------------------	--

2. GAMME (suite)


Extended 2-station plates (4/5 modules)

	Matte Black Storm blue Ash grey Almond white	CP0108 CP0908 CP1008 CP1108	
---	---	--------------------------------------	--

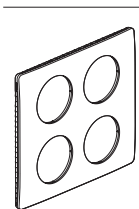
Extended 3-station plates (6/8 modules)

	Matte Black Storm blue Ash grey Almond white	CP0111 CP0911 CP1011 CP1111	
---	---	--------------------------------------	--

1 module plate

	Matte Black	CP0113	
---	-------------	--------	--

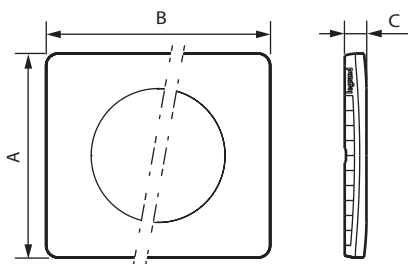
2 x 2-gang plates

	Matte Black	CP0109	
---	-------------	--------	--

2 x 3-gang plates

	Matte Black	CP0110	
--	-------------	--------	--

3. DIMENSIONS (mm)



References	A	B	C
CP0101/121 - CP0901/921 - CP1001/021 - CP1101/121	82	90	9
CP0102/122 - CP0902/922 - CP1002/022 - CP1102/122	82	161	9
CP0103/123 - CP0903/923 - CP1003/023 - CP1103/123	82	232	9
CP0104/124 - CP0904/924 - CP1004/024 - CP1104/124	82	303	9
CP0106 - CP0906 - CP1006 - CP1106	82	147	9
CP0107 - CP0907 - CP1007 - CP1107	82	204	9
CP0108 - CP0908 - CP1008 - CP1108	82	161	9
CP0109	159	175	9
CP0110	159	246	9
CP0111 - CP0911 - CP1011 - CP1111	82	232	9
CP0113	82	41.5	9

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Protection against impacts: IK 04

■ 4.2 Material characteristics

Plate: painted PC + frosted varnish

Sub-plate: black or white ABS

Halogen-free

UV-resistant

Self-extinguishing: 650°C/30 s

■ 4.3 Climate characteristics

Storage temperature: - 10°C to + 70°C

Usage temperature: - 5°C to + 50°C

5. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to the following products:

Hexane, methylated spirit, soapy water, window-cleaning products.

Caution: Always test before using other special cleaning products

No paint should be applied to the plates.

6. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.

See e-catalogue.