


Céliane™ Waterproof plates

Cat. No(s): CP2701/02 - CP2801/02

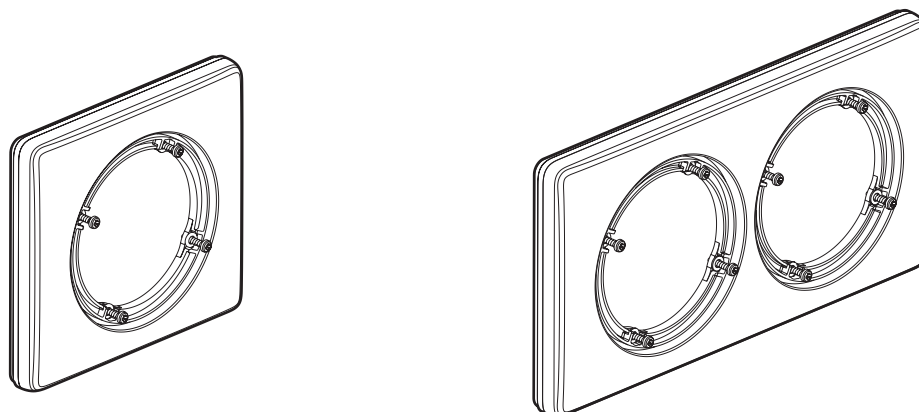

1. USE

Waterproof plates intended for damp premises.
 Allows the covering of mechanisms with 1 to 2 positions.
 Indoor use only.
 Horizontal or vertical mounting on Batibox box.

2. RANGE

1-gang plates

Delivered with Pozidrive cross-head screws for thermoplastics and washers.


	White Ivory	CP2701 CP2801
---	----------------	------------------

2-gang plates - Center distance 71 mm

Delivered with Pozidrive cross-head screws for thermoplastics and washers.

	White Ivory	CP2702 CP2802
---	----------------	------------------

3. DIMENSIONS (mm)

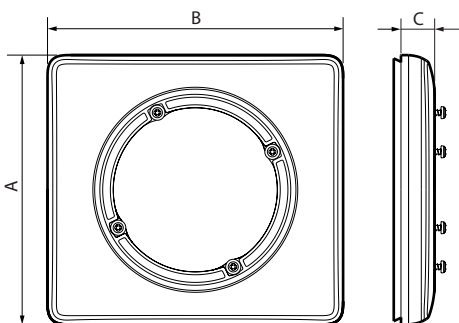

References	A	B	C
CP2701 - CP2801	89	97	11
CP2702 - CP2802	89	168	11

4. TECHNICAL CHARACTERISTICS

■ 4.1 Mechanical characteristics

Protection against impact: IK 04
 Protection against solid bodies and liquids: IP 44
 Mechanical resistance of screws: 2.34 Nm

■ 4.2 Material characteristics

Screws and washers: Steel
 Seal: SEBS

Plates : White PC
 Ivory PC RAL 1013

Sub-plate: ABS

Halogen-free
 UV-resistant

Self-extinguishing: 650°C/30 s

■ 4.3 Climate characteristics

Storage temperature: -10°C to +70°C
 Usage temperature: -5°C to +50°C

5. CARE

Clean the surface with a cloth.
 Do not use acetone, tar-removing cleaning agents or trichloroethylene.
 Resistant to the following products: Hexane (EN 60669-1), methylated spirit, soapy water, diluted ammonia, bleach diluted to 10%, window-cleaning products, pre-impregnated wipes

Caution: Always test before using special cleaning products.

No paint should be applied to the plates.

6. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.
 See e-catalogue