


# Céliane™

## Blanking plates

Cat. No(s): CB0210 - CN0210 - CI0210 - CT0210

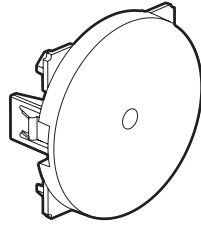


### 1. USE

Allows you to put a function on hold.  
 Possibility of drilling for use as a wire outlet or other adaptation.  
 Attaches directly to Batibox support.  
 To be fitted with a Céliane finishing plate.

### 2. RANGE

	White	Matte Black	Ivory	Titanium
Blanking plate - 2 modules	CB0210	CN0210	CI0210	CT0210

### 3. DIMENSIONS (mm)

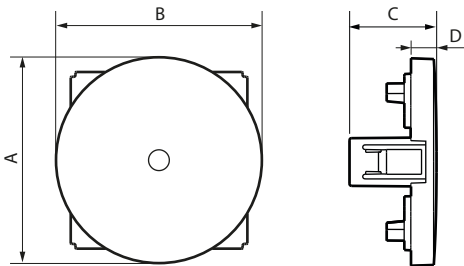

A	B	C	D
53	53	22	6.5

### 4. TECHNICAL CHARACTERISTICS

#### ■ 4.1 Mechanical characteristics

Protection against solid bodies and liquids: IP 20  
 Protection against impact: IK 04

#### ■ 4.2 Material characteristics

Claws: Steel  
 Blanking plate: ABS  
 White RAL 9003  
 Ivory RAL 1013  
 Painted Matt Black satin finish RAL 9017  
 Painted Titanium RAL 7030  
 Halogen-free  
 UV-resistant

Self-extinguishing: 650°C/30 s

#### ■ 4.3 Climate characteristics

Storage temperature: -10°C to +70°C  
 Usage temperature: -5°C to +35°C

### 5. CARE

Clean the surface with a cloth.  
 Do not use acetone, tar-removing cleaning agents or trichloroethylene.  
 Resistant to the following products:  
 Hexane, methylated spirit, soapy water, diluted ammonia, bleach diluted to 10%, windowcleaning products, pre-impregnated wipes

**Caution:** Always test before using special cleaning products.

### 6. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.  
 See e-catalogue