


Céliane™ with Netatmo Connected 2-gang ON/OFF wireless control for lighting and sockets

Cat. No(s): 1 991 69/79/89

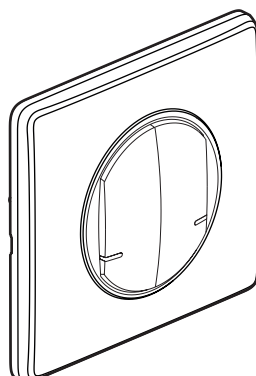

1. USE

Wireless control for 2 ON/OFF light functions or connected socket.
Controls micromodule products, connected sockets and connected dimmer switches.

Can be used as a two-way switch or to control a lighting group.

- Fixes directly on the wall or screws onto a flush-mounting box.
- Multi-gang versions can be combined with other wiring accessories.


- Fits on a piece of furniture (movable).

Can control up to 2 x 20 micromodules, connected sockets, connected dimmer switches.

2. RANGE



Description	White	Titanium	Graphite
2-gang wireless lighting and socket control for an ON/OFF, dimmer, centralisation function. Supplied with battery. With LED indicator (configuration) and RESET button (hidden) used to return to factory settings. Repositionable self-adhesive fixings supplied.	1 991 69	1 991 79	1 991 89

3. DIMENSIONS (mm)

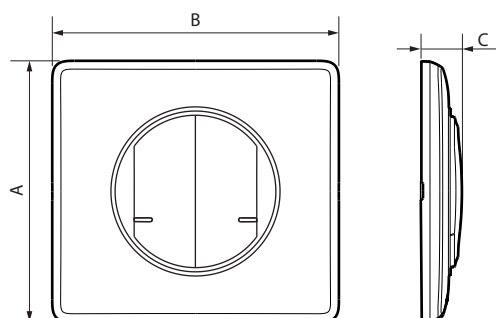

A	B	C
82	90	13

4. OPERATION

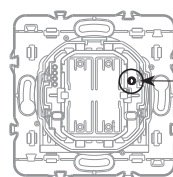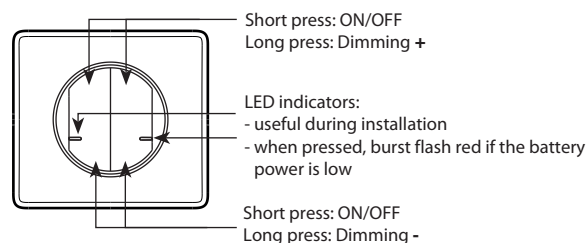

RESET button used to return to factory settings

5. TECHNICAL CHARACTERISTICS

■ 5.1 Mechanical characteristics

Protection against impacts: IK 02

Protection against solid bodies/liquids: IP 20 without plate or rocker plate
IP 40 for assembled product

■ 5.2 Material characteristics

Mechanism casing with grid: Fibreglass-reinforced (10%) PC

Colour	White	Titanium	Graphite
Plate	ABS + PC	ABS + metal	ABS + metal
Rocker plate	ABS	Painted ABS	Painted ABS

Halogen-free

UV-resistant

Self-extinguishing: 650°C/30 s

■ 5.3 Electrical characteristics

Powered by a CR2032 - 3 V lithium battery (supplied)

Battery life: 8 years for 10 activations a day

ZigBee radio technology

Frequency: 2.4 GHz to 2.4835 GHz

Power level: < 100 mW

■ 5.4 Climate characteristics

Usage temperature: +5°C to +45°C

Storage temperature: 0°C to +45°C

6. CARE

Clean the surface with a cloth.

Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Resistant to the following products:

Hexane (EN 60669-1), methylated spirit, soapy water, diluted ammonia, bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

Caution: Always test before using special cleaning products.



Take care to recycle the battery appropriately

7. ACCESSORIES

0 648 71: Repositionable adhesives for wireless control (supplied)

8. STANDARDS AND APPROVALS

The undersigned, LEGRAND, declares that the radio-electric equipment type (1 991 69/79/89) complies with directive 2014/53/EU.

The full text of the EU declaration of conformity is available on the following website: **www.legrandoc.com**