 
 


Socket covers



KW89N
KM89N
KG89N



KW90N
KM90N
KG90N


1. USE

Covers for sockets mechanisms with 1M or 2M modules.

2. RANGE

Socket 5P CHINA STD. Cover 2M	
KW89N	<input type="checkbox"/> White
KM89N	<input type="checkbox"/> Sand
KG89N	<input type="checkbox"/> Black
Socket 2P CHINA STD. Cover 1M	
KW90N	<input type="checkbox"/> White
KM90N	<input type="checkbox"/> Sand
KG90N	<input type="checkbox"/> Black

3. DIMENSIONS (mm)

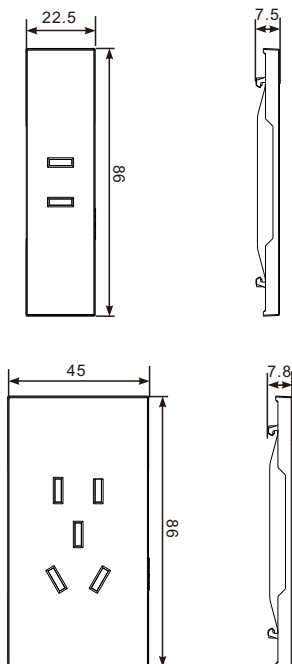

4. TECHNICAL CHARACTERISTICS

4.1 Material characteristics

Material: PC
Halogen free
UV resistant
Self-extinguishing:
+ 850° C / 30 s for insulating parts holding live parts in place.
+ 650° C / 30 s for other parts made of insulating materials.

4.2 Climatic characteristics

Storage temperatures: -5°C to +35°C
Operating temperatures: -5°C to +35°C

4.3 Mechanical characteristics

Impact test: IK04
Protection against solids & liquids: IP20

5. CLEANING

Surface cleaning with a soft, slightly damp cloth.
Do not use: acetone, tar remover, trichloroethylene.

A preliminary test should be carried out if other specific cleaning products are to be used.

6. CONFORMITY - APPROVALS

Compliance with installation and manufacturing standards.
Refer to e-catalogue.