


Arteor™

2 x 2-way switch for bed lights

Cat. No(s): 5 732 94 - 5 737 62/63/94

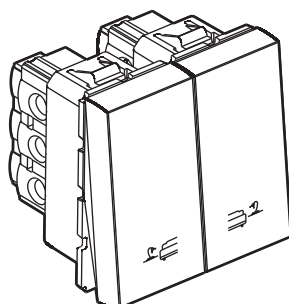

1. USE


Switch for bed lights 2 x 1 module.
 Supplied with rocker plates.
 To be equipped with support frame and plate.
 Flush-mounting or surface-mounting.

2. RANGE

2 x 2-way switch (square) with icons - 2 x 1 module

White	Magnesium	Soft Alu	Champagne
5 732 94	5 737 94	5 737 62	5 737 63

3. OVERALL DIMENSIONS (mm)

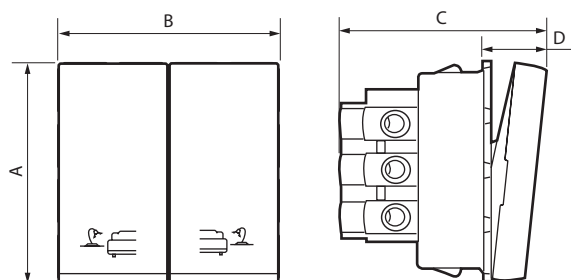

A	B	C	D
45	45	42	13

4. CONNECTION

Terminals: with screws
 Capacity: 2 x 2.5 mm² or 1 x 4 mm²
 Stripping length: 10 mm
 Screwdriver: 4 mm flat-blade up to 5.5 mm

5. TECHNICAL CHARACTERISTICS

■ 5.1 Mechanical characteristics

Protection against solid bodies and liquids: IP 20 (alone)
 IP 40 (mounted)

Impact test: IK 04

■ 5.2 Material characteristics

Material: Rocker: PC
 Mechanism casing: PC
 Basket: PP

Halogen-free

UV-resistant

Self-extinguishing:

850°C/30 s for insulating components holding live parts in place
 650°C/30 s for other insulating components

■ 5.3 Electrical characteristics

Voltage: 250 V~

Current: 10 AX

Max. power for self-ballasted lamps: 100 W

Frequency: 50/60Hz

■ 5.4 Climate characteristics

Storage temperature: - 10°C to + 70°C

Usage temperature: - 5°C to + 50°C

6. MAINTENANCE

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to cleaning products: Hexane (EN 60669-1), Methylated spirit, Soapy water, Diluted ammonia, Pure bleach diluted to 10%, Window-cleaning products, Pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

7. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.

See e. catalogue.