


## Céliane™ 2 P+E socket to US standard

Cat. No(s): CM0131

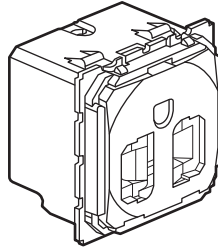


### 1. DESCRIPTION

2 P+E socket to US standard.  
 Can be flush-mounted or surface-mounted in a minimum 40 mm deep box.

### 2. RANGE

Designation	Cat. No
2 P+E socket - 2 modules To be equipped with support frame, face plate and finishing plate.	CM0131

### 3. DIMENSIONS (mm)

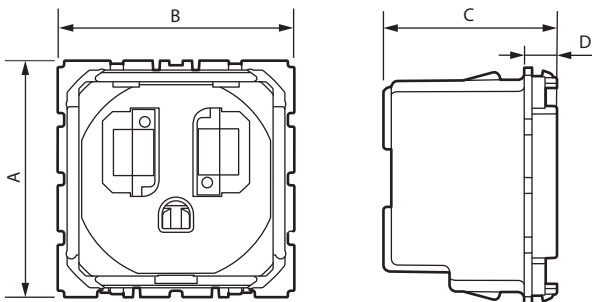

A	B	C	D
45	45	33.5	6

### 4. CONNECTION

3 terminals  
 Type of terminals: with screws  
 Terminal capacity: 2 x 4 mm<sup>2</sup>  
 Stripping length: 9 mm

### 5. TECHNICAL CHARACTERISTICS

#### ■ 5.1 Mechanical characteristics

Protection against solid bodies and liquids: IP 20  
 Protection against impacts: IK 04

#### ■ 5.2 Material characteristics

Base: Polycarbonate

Cover plate: Polycarbonate

Halogen-free

Self-extinguishing:

850°C/30 s for insulating components holding live parts in place.  
 650°C/30 s for other insulating components.

#### ■ 5.3 Electrical characteristics

Voltage: 127 V~

Current: 15 A

#### ■ 5.4 Climate characteristics

Storage temperature: -10°C to +70°C

Usage temperature: -5°C to +50°C

### 6. CLEANING

Surface cleaning with a cloth.

### 7. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.  
 See e-catalogue.