


Céliane™

Easy-to-handle socket outlet

Cat. No(s): CB0117 - CT0117

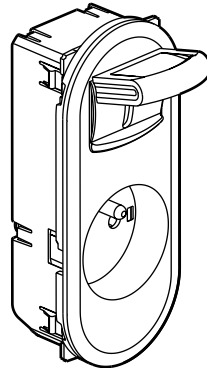

1. USE


2 P+E socket outlet to franco-belgian standard, specially adapted for ease of use.

Equipped with a lever to make the insertion and removal of the plug easier. Can be flush-mounted or surface-mounted in a minimum 40 mm deep box.

2. RANGE

| Designation | White | Titanium |
|--|--------|----------|
| 2 P+E socket delivered with cover plate 5 modules | CB0117 | CT0117 |

3. DIMENSIONS (mm)

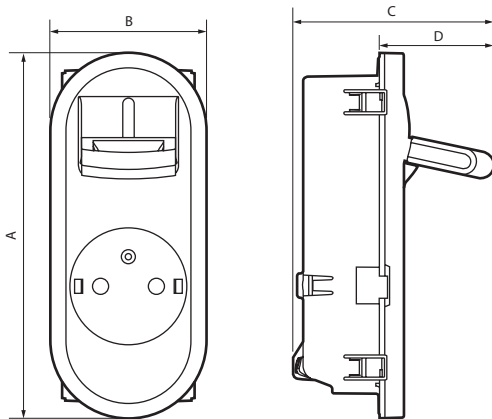

| A | B | C | D |
|-----|----|----|------|
| 124 | 53 | 69 | 39.5 |

4. CONNECTION

Type of terminals : automatics
 Terminal capacity: 2 x 2.5 mm²
 Stripping length: 13 mm

5. FUNCTION

Actuating the lever: reduces the effort needed to insert a plug makes removal of the plug easier.

Maximum effort needed to move lever: 22 N (maximum effort advised by specialist: 30 N).

When the lever is not actuated, the socket operates as a traditional 2P+E socket outlet.

6. TECHNICAL CHARACTERISTICS

■ 6.1 Mechanical characteristics

Protection against solid bodies and liquids: IP 20
 Protection against impacts: IK 04

■ 6.2 Material characteristics

Mechanism casing: PC
 Cover plate: PC
 Halogen-free

■ Self-extinguishing:

850°C/30 s for insulating components holding live parts in place.
 650°C/30 s for other insulating components.

■ 6.3 Electrical characteristics

Voltage: 250 V~
 Current: 16 A

■ 6.4 Climate characteristics

Storage temperature: -10°C to +70°C
 Usage temperature: -5°C to +50°C

7. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Resistance to following products:

Hexane, methylated spirit, soapy water, diluted ammonia, bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.
 Anios, Surfianos, Bactilycine, diluted hydrogen peroxide (35%).

Caution: Always test before using other special cleaning products.

8. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.
 See e-catalogue.