


Céliane™ 2 P+E power socket to British standard

Cat. No(s): CM0160

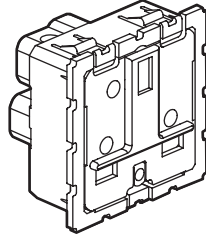


1. USAGE

2 P+E power socket to British standard.
 Surface or flush mounting in box depth min. 40 mm.
 Fixing with clips.

2. RANGE

Description	Cat. No.
2 P+E socket outlet - 2 modules To be equipped with support frame, face plate and finishing plate.	CM0160

3. DIMENSIONS (mm)

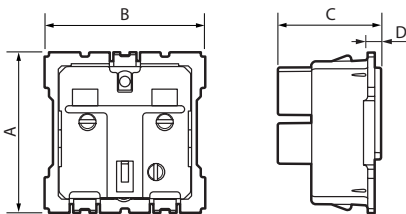

A	B	C	D
45	45	29	4

4. CONNECTION

Type of terminals: oblong hole
 Terminal capacity: 2 x 4 mm²
 Stripping length: 9 mm

5. TECHNICAL CHARACTERISTICS

- **5.1 Mécanical characteristics**
 Impact tests: IK 04
 Penetration by solid bodies and liquids: IP 20
- **5.2 Material characteristics**
 Mécanisme casing: PC
 Halogen-free
 Self-extinguishing:
 850°C/30 s for insulating components holding live parts in place
 650°C/30 s for other insulating components
- **5.3 Electrical characteristics**
 Voltage: 250 V~
 Current: 13 A
- **5.4 Climate characteristics**
 Storage temperature: -10°C to +70°C
 Usage temperature: -5°C to +50°C

6. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.
 See e-catalogue.