


Céliane™ Markup light

Cat. No(s): CM0281

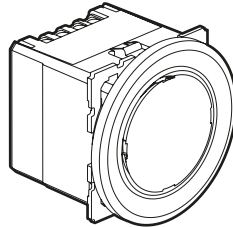


1. USE

Signalling devices with LEDS lighting.
Surface or recessed mounting in box depth 40 mm minimum.
To be combined with a Batibox universal support and a Céliane finishing plate.

2. RANGE

| Description | Cat. No. |
|--|----------|
| Signalling device delivered with support frame and opalescent cover plate. With circular blue LED lighting in standby mode. Automatically turns on in the event of a power outage (white LED). | CM0281 |

3. DIMENSIONS (mm)

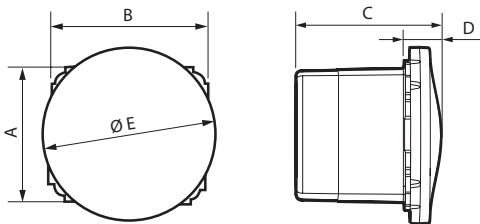

| A | B | C | D | Ø E |
|----|----|------|----|-----|
| 45 | 45 | 43.5 | 11 | 53 |

4. CONNECTION

Type of terminals: with screws
Terminals capacity: 2 x 1.5 mm²
Stripping length: 11 mm
Screwdriver: flat 3.5 mm
Flexible or rigid cables compatible

5. TECHNICAL CHARACTERISTICS

■ 5.1 Mechanical characteristics

Protection against impacts: IK 04
Protection against solide bodies and liquids: IP 20

■ 5.2 Material characteristics

Diffuser: ABS Opalescent white
Mechanism casing: PC

Halogen-free
UV-resistant

Self-extinguishing:

850°C/30 s for components holding live parts in place.
650°C/30 s for other insulating components.

■ 5.3 Electrical characteristics

Voltage: 230 V~
Frequency: 50/60 Hz
Power: 0.2 W or 1 W
Flux lumineux : 1,5 lumen

Battery: Ni-MH

2,4 V~ - 300 mAh

2/3 AAA

Autonomy 1 h maximum

■ 5.4 Climate characteristics

Storage temperature: 0°C to +50°C
Usage temperature: -5°C to +35°C

6. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Caution: Always test before using other special cleaning products.



Take care to recycle the battery appropriately

7. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.
See e-catalogue.