


SEANO™ IP44 plate for key switch

Cat. No(s): 7 651 17

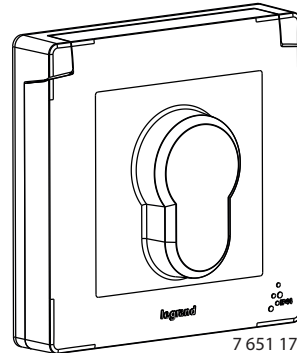


1. USE

Frame plates white color supplied with translucent cover for fitting on SEANO mechanisms.

2. RANGE

IP44 plate for key switch	White	7 651 17
---------------------------	-------	----------

3. DIMENSIONS (mm)

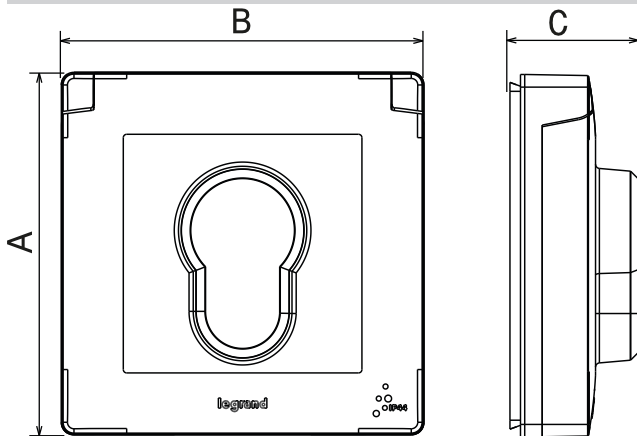

References	A	B	C
7 651 17	86	86	30,7

4. MOUNTING

The plates snap onto the socket adapter or the switch cover. In case of the sockets, the socket cover clamp the frame.

5. TECHNICAL DATA

- 5.1 Mechanical characteristics
180° opening capacity of the cover
Impact tests: IK 04
Penetration against solid bodies and liquids: IP 44

■ 5.2 Material characteristics

- Plates: PC
- Molded white: RAL9003
- Under-plates: PC
- UV resistant
- Halogen free
- Self-extinguishing: 650° C / 30 s

■ 5.3 Climatical characteristics

- Storage temperature: - 10° C to + 70° C
- Use temperature: - 5° C to + 50° C

6. CLEANING

Surface cleaning with a cloth. Do not use: acetone, tar remover, trichloroethylene.

■ 6.1 Resistance to the following cleaning substances

- Hexane (EN 60669-1),
- Methylated spirit,
- Soapy water,
- Diluted ammonia,
- Diluted pure bleach 10%,
- Glass cleaning product,
- Pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

7. SPECIAL USE

The plates must not be painted.