


SEANO™
Double socket outlets - German standard

Cat. No(s): 7 65X 25

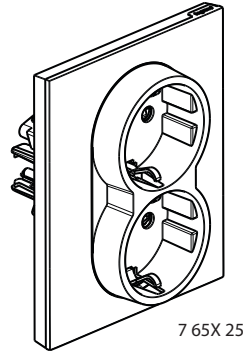

7 65X 25


1. USE

Double socket outlets 16 A - 250 V~ with shutters.
 Mechanisms supplied with support and protection cover
 Installation in 1-gang flush-mounting or surface-mounting box, allows
 replacing 1 socket by 2 sockets without changing mounting box.
 To be equipped with plates

2. RANGE

Description	White	Aluminum	Black	Dark grey
2X2P+E socket schuko standard auto terminals shuttered	7 651 25	7 652 25	7 653 25	7 654 25

3. DIMENSIONS (mm)

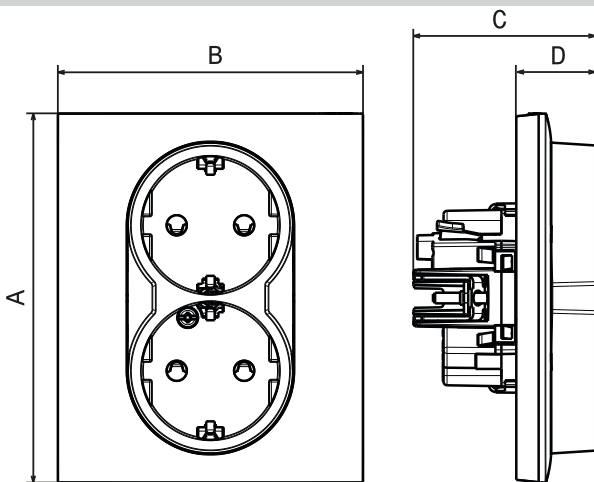

References	A	B	C	D
7 65X 25	104	86	51,3	22,95

4. CONNECTION

Flexible or rigid cables compatible
 Auto terminal
 Stripping length:
 13 mm
 Capacity:
 2 x 2.5 mm²

5. TECHNICAL CHARACTERISTICS

■ **5.1 Mechanical characteristics**
 Protection against solid bodies and liquids IP20
 Protection against impact: IK 04

■ **5.2 Material characteristics**
 Polygloss appearance

Colours: - White RAL9003
 -Aluminium C010B
 -Black C014A

Double socket outlets - German standard

-Dark grey C008A

Material: - Plate Polycarbonate
- Socket cover plate: Polycarbonate
- Halogen-free
- UV-resistant

Material of the support:
- Metal

Self-extinguishing:
+ 850°C/30 s for insulating components holding live parts in place
+ 650°C/30 s for other insulating components.

■ 5.3 Electrical characteristics

Voltage: 250 V~
Current: 16 A
Frequency: 50/60 Hz

■ 5.4 Climate characteristics

Storage and usage temperature:
- 5 °C to + 35 °C (7 21X 26, 7 21X 82)
Storage and usage temperature:
- 10 °C to + 70 °C (7 21X 90)
Storage and usage temperature:
- 25 °C to + 40 °C (7 21X 91)

6. MAINTENANCE

Surface cleaning with a cloth.

Do not use:
Acetone, tar remover, trichloroethylene.

Maintenance with the following products:
Hexane (EN 60669-1), Methylated spirit, Soapy water, Diluted ammonia, pure bleach diluted to 10%, Window-cleaning products, pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

7. STANDARDS AND APPROVALS

Compliance with standards of installation and manufacturing.
Refer to e-catalogue.