


SEANO™ IP44 plates

Cat. No(s): 7 65X 44

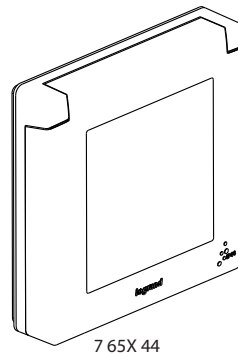

7 65X 44


1. USE

Frame plates white color supplied with translucent cover for fitting on SEANO mechanisms.

2. RANGE

| | | |
|------------|-----------|----------|
| IP44 plate | White | 7 651 44 |
| | Aluminium | 7 652 44 |
| | Black | 7 653 44 |
| | Dark Grey | 7 654 44 |

3. DIMENSIONS (mm)

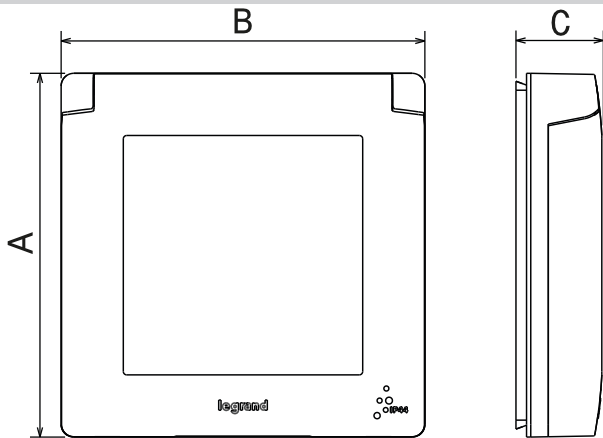

| References | A | B | C |
|------------|----|----|------|
| 7 65X 44 | 86 | 86 | 20,3 |

4. MOUNTING

The plates snap onto the socket adapter or the switch cover. In case of the sockets, the socket cover clamp the frame.

5. TECHNICAL DATA

- 5.1 Mechanical characteristics
 180° opening capacity of the cover
 Impact tests: IK 04
 Penetration against solid bodies and liquids: IP 44

■ 5.2 Material characteristics

- Plates: ABS
- Shutter for plate: PC
- UV resistant
- Halogen free
- Self-extinguishing: 650° C / 30 s

■ 5.3 Climatical characteristics

- Storage temperature: - 10° C to + 70° C
- Use temperature: - 5° C to + 50° C

6. CLEANING

Surface cleaning with a cloth. Do not use: acetone, tar remover, trichloroethylene.

■ 6.1 Resistance to the following cleaning substances

- Hexane (EN 60669-1),
- Methylated spirit,
- Soapy water,
- Diluted ammonia,
- Diluted pure bleach 10%,
- Glass cleaning product,
- Pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

7. SPECIAL USE

The plates must not be painted.