



SEANO™ Socket outlets-German standard

Cat. No(s): 7 65X 96 / 765X 90

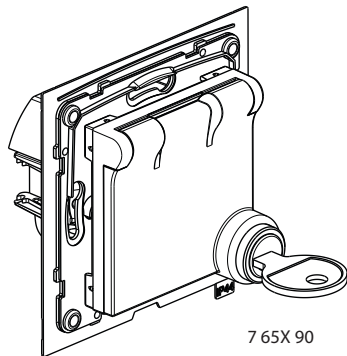

7 65X 90

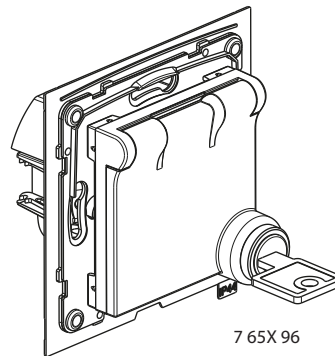

7 65X 96


1. USE

Socket outlets with shutters.
 Flush-mounting.
 Screw and/or claw fixing.
 The products delivered with different or alike lock mechanism.
 Round shape key is randomised. Square shape key is unique numbered 2A28.


2. RANGE

Description	White	Aluminium	Black	Dark Grey
IP 44 2P+E SOCKET AUTO TERMINAL WITH KEYED ALIKE LOCK	7 651 96	7 652 96	7 653 96	7 654 96
IP 44 2P+E SOCKET AUTO TERMINAL WITH DIFFERENTLY KEYED LOCK	7 651 90	7 652 90	7 653 90	7 654 90

3. DISMANTLING

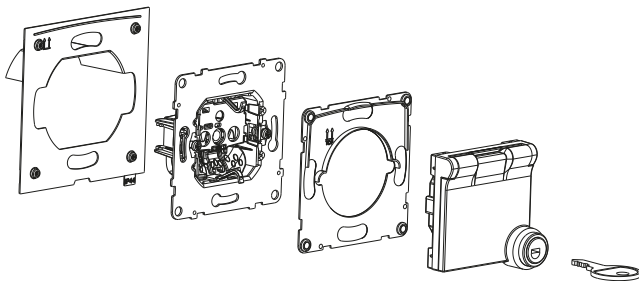

4. DIMENSIONS (mm)

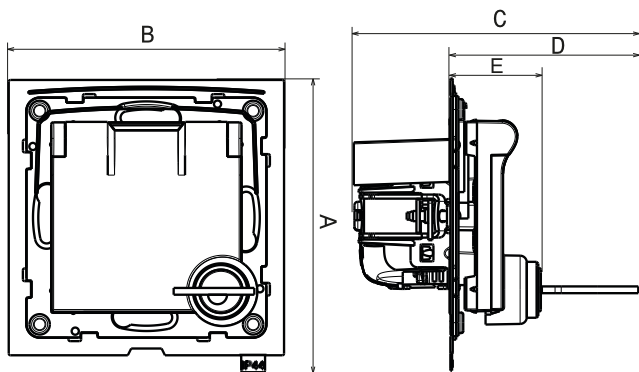

References	A	B	C	D	E
7 65X 90/96	81.25	81.25	83.95	54.75	26

5. CONNECTION

Flexible or rigid cables compatible.

Terminal capacity:
 6 x 2,5mm²
 Stripping length:
 13mm

6. TECHNICAL CHARACTERISTICS

■ 6.1 Mechanical characteristics

Protection against solid bodies and liquids: IP 44
 Protection against impact: IK 04

■ 6.2 Material characteristics

Polygloss appearance
 Color molded: White RAL 9003

Mat appearance
 Painted black C14A
 Painted aluminium C010B
 Painted dark grey C008A

Material:

- Flap: PC
- Halogen-free
- UV resistant

- Socket covers: PC
- Halogen-free
- UV resistant

Self-extinguishing:
 850°C/30 s for installing components holding live parts in place
 650°C/30 s for other insulating components

6. TECHNICAL CHARACTERISTICS (continued)

■ 6.3 Electrical characteristics

Voltage: 250 V~

Current: 16 A

Frequency: 50/60 Hz

■ 6.4 Climatic characteristics


Usage temperature: - 5°C to + 35°C

Storage temperature: - 10°C to + 70°C

■ 6.5 Support

Material of the support: Metal

Angular adjusting:

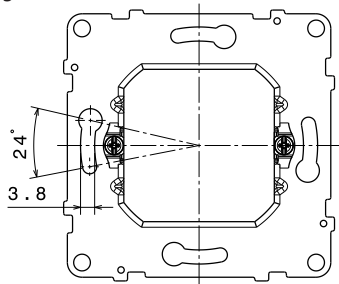


■ 6.6 Fixing with claws

Number of turns to open the claws:

- 58 mm > 2.1 turns

- 65 mm > 2.75 turns

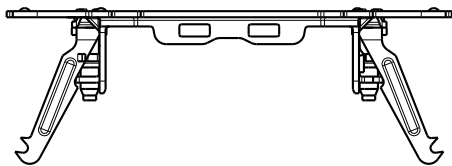

■ 6.7 Cover fixing

Fixing with screw maximum 1 Nm tightening

7. MAINTENANCE

Surface cleaning with a cloth.

Do not use:

Acetone, tar remover, trichloroethylene.

Maintenance with the following products:

Hexane, Methylated spirit, Soapy water, Diluted ammonia, Bleach diluted to 10%, Window-cleaning products.

Caution: Always test before using other special cleaning products.

8. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.

Refer to e-catalogue.