


SEANO™
RGB Dimmer DALI

Cat. Nos: 7 651 45, 7 653 45

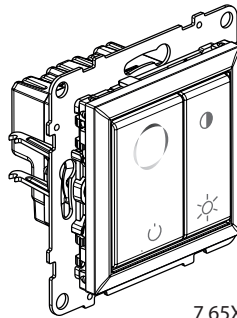

7 65X 45


1. USE

RGB dimmer colour-lighting management allows the user to create lighting ambiances. The product is equipped with on/off, saturation and brightness buttons.


2. RANGE

| Description | White | Black |
|-----------------|----------|----------|
| RGB Dimmer DALI | 7 651 45 | 7 653 45 |

4. DIMENSIONS (mm)

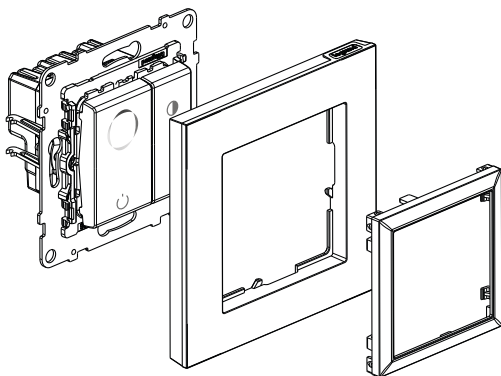

4. DIMENSIONS (mm)

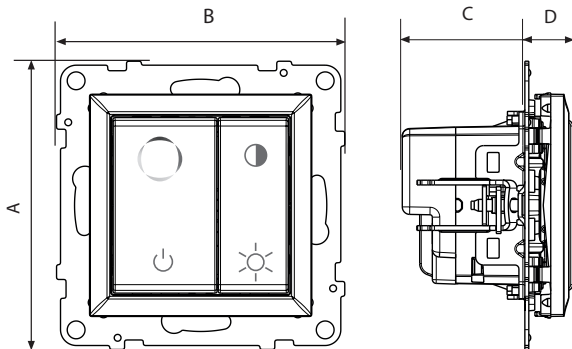

| References | A | B | C | D |
|------------|------|------|------|------|
| 7 65X 45 | 72,9 | 72,9 | 43,1 | 12,1 |

4. DIMENSIONS (mm)

4 terminals with screws
 Terminal capacity: 2 x 2.5 mm²
 Stripping length: 8 mm

5. TECHNICAL CHARACTERISTICS

■ **5.1 Mechanical characteristics**

Protection against solid/bodies and liquids: IP 40
 Protection against impacts : IK 04

■ **5.2 Material characteristics**

Polygloss appearance
 Colour: - White RAL 9003

Matt appearance
 Painted black RAL 9007

Material:
 Rockers: ABS
 Material of the support: Metal

Halogen-free
 UV-resistant


Self-extinguishing:
 850°C/30 s for insulating components holding live parts in place
 650°C/30 s for other insulating components

■ **5.3 Electrical characteristics**

Voltage: 100 to 240 V~
 Frequency: 50/60 Hz


■ **6.5 Support**

Material of support: -Metal
 Angular adjusting:

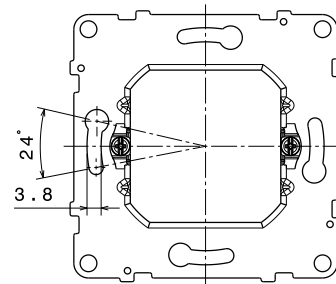

■ **6.6 Fixing with claws**

Number of turns to open the claws:
 - 58 mm > 2,1 turns
 - 65 mm > 2,75 turns

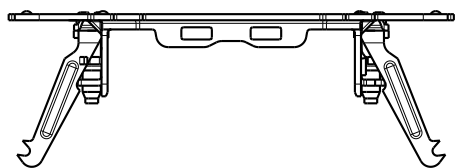

■ 5.4 Climate characteristics

Storage temperature: -10°C to +70°C

Usage temperature: -5°C to +35°C

6. MAINTENANCE

Surface cleaning with a cloth.

Do not use:

Acetone, tar remover, trichloroethylene.

Maintenance with the following products:

Hexane, Methylated spirit, Soapy water, Diluted ammonia, Bleach diluted to 10%, Window-cleaning products, Pre-impregnated wipes.

Caution: Always test before using other special cleaning products.

7. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.

See e-catalogue.