 
 


7 651 71



7 651 72

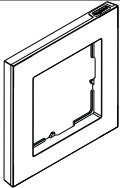
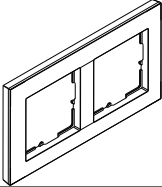
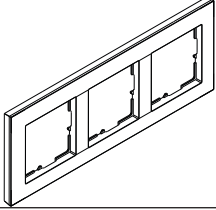
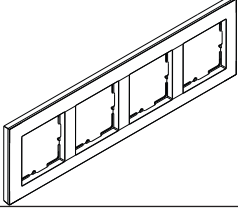
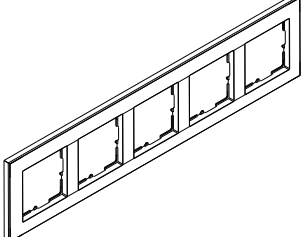


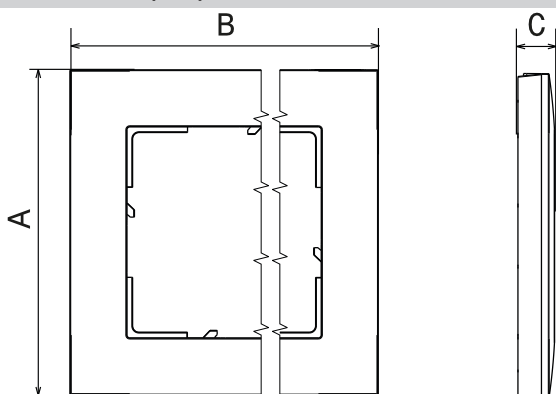
7 651 73

1. USE

Frame plates for fitting on SEANO mechanisms.

2. RANGE

	Gang	Colour	Reference number
	1 Gang	White	7 651 71
	2 Gang	White	7 651 72
	3 Gang	White	7 651 73
	4 Gang	White	7 651 74
	5 Gang	White	7 651 75

3. DIMENSIONS (mm)

References	A	B	C
7 651 71	87	87	9,8
7 651 72	87	158	9,8
7 651 73	87	229	9,8
7 651 74	87	301	9,8
7 651 75	87	372	9,8

4. MOUNTING

The plates snap onto the socket adapter or the switch cover. In case of the sockets, the socket cover clamp the frame.

5. TECHNICAL DATA**■ 5.1 Mechanical characteristics**

Mechanical characteristics
Impact tests: IK 04

■ 5.2 Material characteristics

Plates: ABS
UV resistant
Halogen free

Self-extinguishing: 650° C / 30 s

5.3 Climatical characteristics

Storage temperature: - 10° C to + 70° C

Use temperature: - 5° C to + 40° C

6. MAINTENANCE

Surface cleaning with a cloth.

Do not use:

Acetone, tar remover, trichloroethylene.

Dish-washer proof.

■ **6.1** - Hexane (EN 60669-1),

- Methylated spirit,

- Soapy water,

- Diluted ammonia,

- Diluted pure bleach 10%,

- Glass cleaning product,

- Pre-impregnated wipes.

■ **6.2** Resistance to the following hospital-type cleaning substances

- Anios,

- Surfanios,

- Bactilyline,

- Hydrogen peroxide (oxygenated water 35%).

Caution: A spot test should be carried out before using any other specific cleaners.

Caution: A spot test should be carried out before using any other specific cleaners.

7. SPECIAL USE

The plates must not be painted.