 
 


7 65X 71



7 65X 72

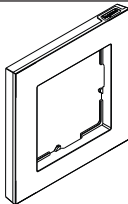
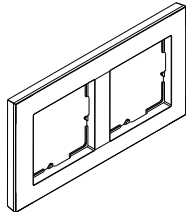
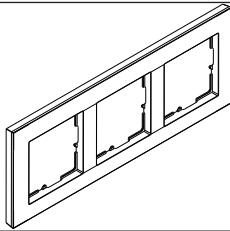
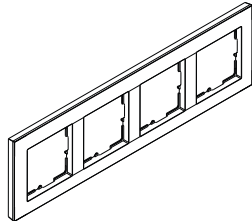
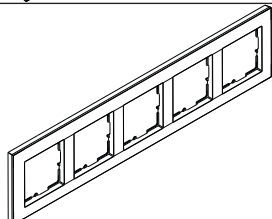


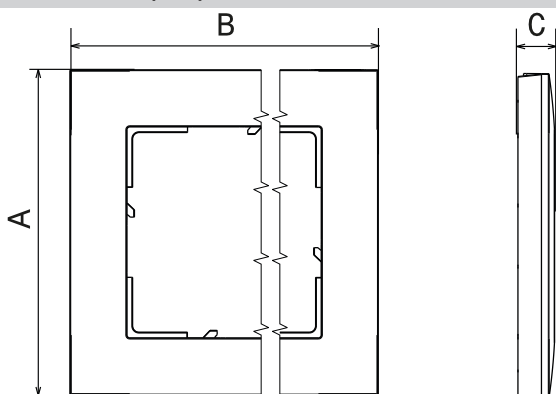
7 65X 73

1. USE

Frame plates for fitting on SEANO mechanisms.

2. RANGE

	Gang	Colour	Reference number
	1 Gang	aluminium	7 652 71
		black	7 653 71
		dark grey	7 654 71
		pearl	7 655 71
	2 Gang	aluminium	7 652 72
		black	7 653 72
		dark grey	7 654 72
		pearl	7 655 72
	3 Gang	aluminium	7 652 73
		black	7 653 73
		dark grey	7 654 73
		pearl	7 655 73
	4 Gang	aluminium	7 652 74
		black	7 653 74
		dark grey	7 654 74
		pearl	7 655 74
	5 Gang	aluminium	7 652 75
		black	7 653 75
		dark grey	7 654 75
		pearl	7 655 75

3. DIMENSIONS (mm)

References	A	B	C
7 651 71	87	87	9,8
7 651 72	87	158	9,8
7 651 73	87	229	9,8
7 651 74	87	301	9,8
7 651 75	87	372	9,8

4. MOUNTING

The plates snap onto the socket adapter or the switch cover. In case of the sockets, the socket cover clamp the frame.

5. TECHNICAL DATA**■ 5.1 Mechanical characteristics**

Mechanical characteristics
Impact tests: IK 04

■ 5.2 Material characteristics

Plates: ABS
UV resistant
Halogen free

Self-extinguishing: 650° C / 30 s

5.3 Climatical characteristics

Storage temperature: - 10° C to + 70° C

Use temperature: - 5° C to + 40° C

6. MAINTENANCE

Surface cleaning with a cloth.

Do not use:

Acetone, tar remover, trichloroethylene.

Dish-washer proof.

■ **6.1** - Hexane (EN 60669-1),

- Methylated spirit,

- Soapy water,

- Diluted ammonia,

- Diluted pure bleach 10%,

- Glass cleaning product,

- Pre-impregnated wipes.

■ **6.2** Resistance to the following hospital-type cleaning substances

- Anios,

- Surfanios,

- Bactilyline,

- Hydrogen peroxide (oxygenated water 35%).

Caution: A spot test should be carried out before using any other specific cleaners.

Caution: A spot test should be carried out before using any other specific cleaners.

7. SPECIAL USE

The plates must not be painted.