


1. USE

Frame plates for fitting on SEANO mechanisms.


2. RANGE

	Gang	Colour	Reference number
	1 Gang	white	7 651 81
		aluminium	7 652 81
		black	7 653 81
		dark grey	7 654 81
		mastic	7 655 81
		titane	7 656 81
	2 Gang	white	7 651 82
		aluminium	7 652 82
		black	7 653 82
		dark grey	7 654 82
		mastic	7 655 82
		titane	7 656 82
	3 Gang	white	7 651 83
		aluminium	7 652 83
		black	7 653 83
		dark grey	7 654 83
		mastic	7 655 83
		titane	7 656 83
	4 Gang	white	7 651 84
		aluminium	7 652 84
		black	7 653 84
		dark grey	7 654 84
		mastic	7 655 84
		titane	7 656 84

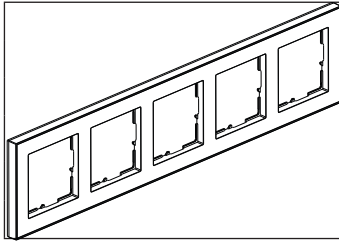

5 Gang	white	7 651 85
	aluminium	7 652 85
	black	7 653 85
	dark grey	7 654 85
	mastic	7 655 85
	titane	7 656 85

3. DIMENSIONS (mm)

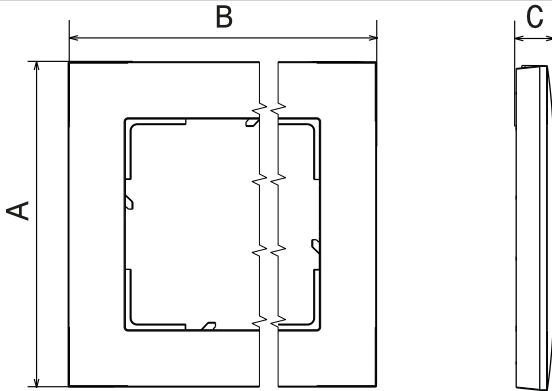

References	A	B	C
7 65X 81	86	86	10
7 65X 82	86	157	10
7 65X 83	86	228	10
7 65X 84	86	299,75	10
7 65X 85	86	371	10

4. MOUNTING

The plates snap onto the socket adapter or the switch cover. In case of the sockets, the socket cover clamp the frame.

5. TECHNICAL DATA

■ 5.1 Mechanical characteristics

IMechanical characteristics
Impact tests: IK 04

■ 5.2 Material characteristics

Plates: ABS
UV resistant
Halogen free

Self-extinguishing: 650° C / 30 s

5.3 Climatical characteristics

Storage temperature: - 10° C to + 70° C
Use temperature: - 5° C to + 40° C

6. MAINTENANCE

Surface cleaning with a cloth.

Do not use:

Acetone, tar remover, trichloroethylene.

Dish-washer proof.

■ 6.1 - Hexane (EN 60669-1),

- Methylated spirit,
- Soapy water,
- Diluted ammonia,
- Diluted pure bleach 10%,
- Glass cleaning product,
- Pre-impregnated wipes.

■ 6.2 Resistance to the following hospital-type cleaning substances

- Anios,
- Surfianos,
- Bactylisine,
- Hydrogen peroxide (oxygenated water 35%).

Caution: A spot test should be carried out before using any other specific cleaners.

Caution: A spot test should be carried out before using any other specific cleaners.

7. SPECIAL USE

The plates must not be painted.