


Urbano™ Roller shutter

Cat. No(s): UB2610GR/WH

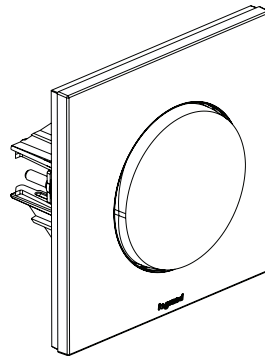

1. USE


Control mechanisms for rolling shutters, blinds, awnings.
 3 positions: up/stop/down.
 The mechanisms are supplied with fingers, supports and plates.
 Equipped with single-post plates.
 Flush mounting mecanismes
 Fixing with claws and/or screws.

2. RANGE

ROLLER SHUTTER 10 AX - 250 V~ - with claws

Description	White	Grey
Two-way roller shutter	UB2610WH	UB2610GR

3. OVERALL DIMENSIONS (mm)

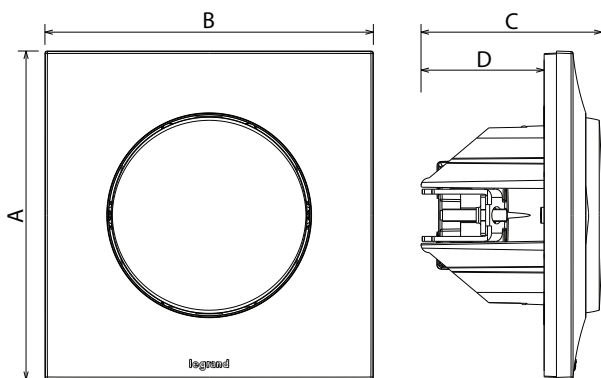

References	A	B	C	D
UB2610GR/WH	80	80	44.1	30

4. CONNECTION

Type of terminals: screw
 Terminal capacity: 1.5 mm² - 2.5 mm² (1 or 2 conductors)
 Stripping length: 8 mm
 Flexible or rigid cables compatible.

5. TECHNICAL CHARACTERISTICS

■ 5.1 Protection index

Protection against solid bodies and liquids: IP20
 Protection against impacts: IK 04

■ 5.2 Material characteristics

 
Front plate, rocker: ABS
 Mechanism, support : PC
 Claws: steel
 UV-resistant
 Halogen-free

Self-extinguishing:

850°C/30 s for insulating components holding live parts in place.
 650°C/30 s for other insulating components.

■ 5.3 Electrical characteristics

Voltage: 250 V~
 Current: 10 AX
 Frequency: 50/60 Hz
 Maximum power on lamps with integrated ballast
 (LED lamps and compact fluorescent): 100 W



■ 5.4 Climate characteristics

Storage temperature: - 10° C to + 70° C
 Use temperature: - 5° C to + 35° C

6. CLEANING

Surface cleaning with a cloth.
 Do not use: acetone, tar remover, trichloroethylene.

Maintenance with the following products: Hexane (EN 60669-1),
 Methylated spirit, Soapy water, Diluted ammonia, Bleach diluted to 10%,
 Window-cleaning products, Pre-saturated wipes.

Caution: A preliminary test should be carried out if other specific
 cleaning products are to be used.

7. STANDARDS AND APPROVALS

Compliance with standards of installation and manufacturing.
 Refer to e.catalogue.