


Urbano™
Rotary dimmer 300W RLC + LEDs

Cat. No(s): UB2410GR/WH

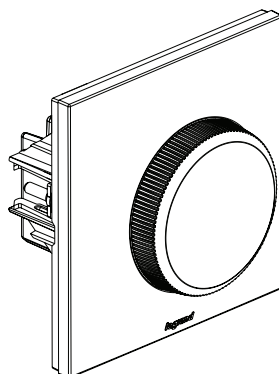


1. USE

Control mechanisms for Light dimming.
 The mechanisms are supplied with rocker, supports and plates.
 Equipped with single-post plates.
 Flush mounting mechanisms
 Fixing with claws and/or screws.

2. RANGE

Description	White	Grey
Rotary dimmer 300 W – 2 wires	UB2410WH	UB2410GR

3. OVERALL DIMENSIONS (mm)

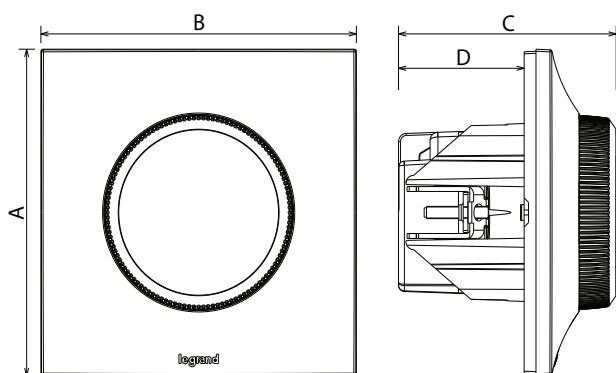

References	A	B	C	D
UB2410GR/WH	80	80	55.2	31.85

4. CONNECTION

Type of terminals: screw
 Terminal capacity: 1.5 mm² - 2.5 mm² (1 or 2 conductors)
 Stripping length: 8 mm
 Flexible or rigid cables compatible.




 





 




5. TECHNICAL CHARACTERISTICS

- **5.1 Protection index**
 Protection against solid bodies and liquids: IP20
 Protection against impacts: IK 04
- **5.2 Material characteristics**
 Front plate, rocker: ABS
 Mechanism, support : PC
 Claws: steel
 UV-resistant
 Halogen-free
 Self-extinguishing:
 850°C/30 s for insulating components holding live parts in place.
 650°C/30 s for other insulating components.
- **5.3 Electrical characteristics**
 Voltage: 110-240 V~
 Frequency: 50/60 Hz

Variateur rotatif 300 W RLC + LEDs

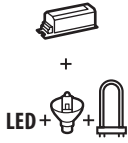5. TECHNICAL CHARACTERISTICS (continued)

■ 5.3 Electrical characteristics (continued)

		R		L	
				^(*) 	^(*) 
					
200 V / 240 V	Maxi	300 W	300 W	300 VA	300 VA
	Mini	5 W	5 W	5 VA	5 VA
100 V / 200 V	Maxi	150 W	150 W	150 VA	150 VA
	Mini	5 W	5 W	5 VA	5 VA
C/L					
					LED 
					
200 V / 240 V	Maxi	300 VA	300 VA	75 W or 10 lamps max	75 W or 10 lamps max
	Mini	5 VA	5 VA	5 W	5 W
100 V / 200 V	Maxi	150 VA	150 VA	37 W or 10 lamps max	37 W or 10 lamps max
	Mini	5 VA	5 VA	5 W	5 W

(*) Only use transformers designed to operate with electronic switches.

■ 5.4 Climate characteristics

Storage temperature: - 10° C to + 70° C

Use temperature: - 5° C to + 40° C

6. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Maintenance with the following products: Hexane, Methylated spirit, Soapy water, Diluted ammonia, Bleach diluted to 10%, Window-cleaning products, Pre-saturated wipes.

Caution: A preliminary test should be carried out if other specific cleaning products are to be used.

7. STANDARDS AND APPROVALS

Conforme aux normes d'installation et de fabrication.

Voir e.catalogue.