
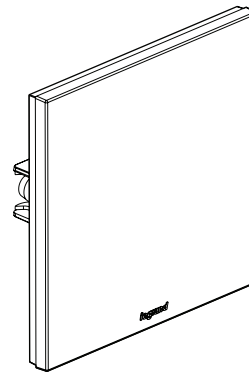


Urbano™ Sutter and Cable outlet

Cat. No(s): UB1510GR/WH - UB3610GR/WH

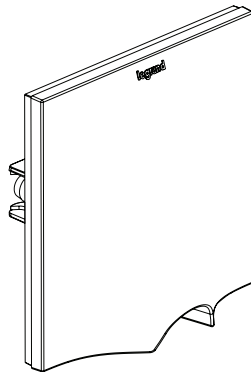


1. USE

The mechanisms are supplied with rocker, supports and plates.
 Equipped with single-post plates.
 Flush mounting mechanisms
 Fixing with claws and/or screws.

2. RANGE

Description	White	Grey
Sutter	UB1510WH	UB1510GR
Cable outlet	UB3610WH	UB3610GR

3. OVERALL DIMENSIONS (mm)

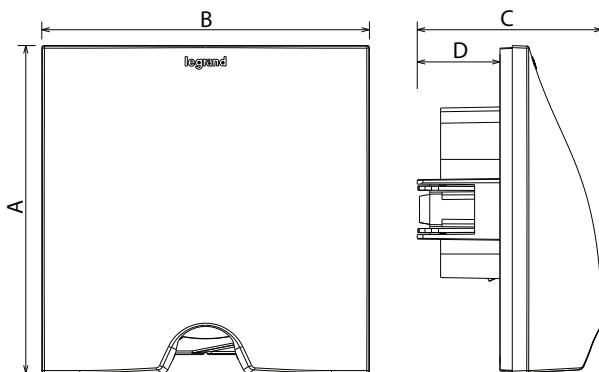

References	A	B	C	D
UB1510GR/WH	80	80	33.2	20.2
UB3610GR/WH	80	80	45.1	20.2

4. TECHNICAL CHARACTERISTICS

■ 4.1 Protection index

Protection against solid bodies and liquids: IP20
 Protection against impacts: IK 04

■ 4.2 Material characteristics

Front plate: ABS
 Mechanism, support : PC
 Claws: steel
 UV-resistant
 Halogen-free

Self-extinguishing:

850°C/30 s for insulating components holding live parts in place.
 650°C/30 s for other insulating components.

■ 4.3 Electrical characteristics

Voltage: 250 V~
 Frequency: 50/60 Hz

■ 4.4 Climate characteristics

Storage temperature: - 10° C to + 70° C
 Use temperature: - 5° C to + 40° C

5. CLEANING

Surface cleaning with a cloth.
 Do not use: acetone, tar remover, trichloroethylene.

Maintenance with the following products: Hexane, Methylated spirit, Soapy water, Diluted ammonia, Bleach diluted to 10%, Window-cleaning products, Pre-saturated wipes.

Caution: A preliminary test should be carried out if other specific cleaning products are to be used.

6. STANDARDS AND APPROVALS

Compliance with standards of installation and manufacturing.
 Refer to e.catalogue.