


Urbano™ USB Type-A + USB Type-C charger

Cat. No(s): UB3510GR/WH

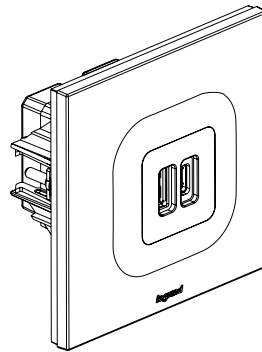


1. USE

Mechanisms for recharging mobile phones, smartphones, tablets, MP3, MP4, speakers, watches, game consoles, power banks.
 The mechanisms are supplied with rocker, supports and plates.
 Equipped with single-post plates.
 Flush mounting mecanismes
 Fixing with claws and/or screws.

2. RANGE

Description	White	Grey
1 USB type-A socket + 1 USB type-C socket	UB3510WH	UB3510GR

3. OVERALL DIMENSIONS (mm)

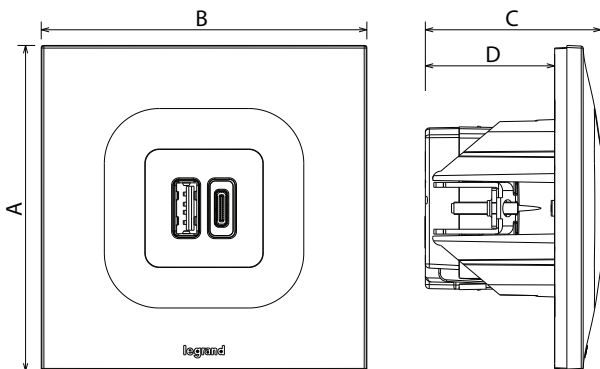

References	A	B	C	D
UB9410GR/WH	80	80	43.2	31.8

4. CONNECTION

Type of terminals: screw
 Terminal capacity: 1.5 mm² - 2.5 mm² (1 or 2 conductors)
 Stripping length: 6 mm
 Flexible or rigid cables compatible.

5. TECHNICAL CHARACTERISTICS

■ 5.1 Protection index

Protection against solid bodies and liquids: IP20
 Protection against impacts: IK 04

■ 5.2 Material characteristics

Front plate, rocker: ABS
 Mechanism, support : PC
 Claws: steel

UV-resistant
 Halogen-free

Self-extinguishing:

850°C/30 s for insulating components holding live parts in place.
 650°C/30 s for other insulating components.

■ 5.3 Caractéristiques climatiques

Température de stockage : - 10° C à + 70° C
 Température d'utilisation : - 5° C à + 40° C

■ 5.3 Electrical characteristics

All values listed below are measured at an ambient temperature of + 25°C and after 15 minutes of operation.

Nominal input voltage	100 - 240 V~
Nominal input frequency	50-60 Hz
Power	15 W
Maximum input current	300 mA
Maximum power consumption in standby	0,075 W
Power average efficiency	80,3 %
Nominal output voltage	5 V ^{DC}
Maximum output current Type-A + Type-C	3 A partagé sur les sorties A et C
Maximum output current Type-C	3 A
No-load power consumption class and average efficiency level: Level VI	
Protection class	II - Low voltage

Note : To optimize the charging time of your device, ensure turn it off during the charging phase.

6. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Maintenance with the following products: Hexane, Methylated spirit, Soapy water, Diluted ammonia, Bleach diluted to 10%, Window-cleaning products, Pre-saturated wipes.

Caution: A preliminary test should be carried out if other specific cleaning products are to be used.

7. STANDARDS AND APPROVALS

Compliance with standards of installation and manufacturing.

Refer to e.catalogue.