


Urbano™ Dismatic 20A

Cat. No(s): UB7310GR/WH

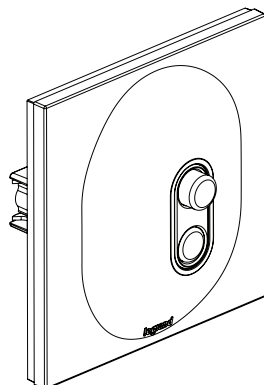


1. USE

Mechanisms for circuit breaking.
The mechanisms are supplied with rocker, supports and plates.
Equipped with single-post plates.
Flush mounting mechanisms
Fixing with claws and/or screws.

2. RANGE

Description	White	Grey
Dismatic circuit breaker 20 A	UB7310WH	UB7310GR

3. OVERALL DIMENSIONS (mm)

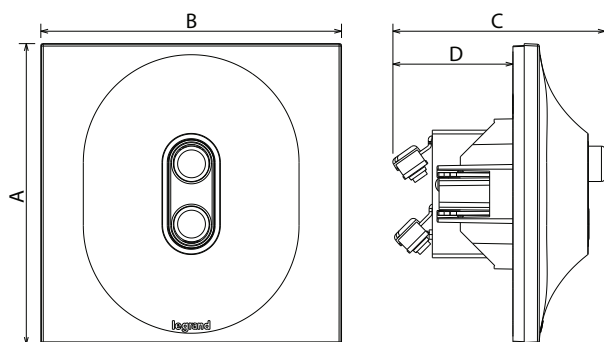

References	A	B	C	D
UB7310GR/WH	80	80	56.5	31.9

4. CONNECTION

Type of terminals: screw
Terminal capacity: 1.5 mm² - 2.5 mm² (1 or 2 conductors)
Stripping length: 8 mm
Flexible or rigid cables compatible.

5. TECHNICAL CHARACTERISTICS

■ 5.1 Protection index

Protection against solid bodies and liquids: IP20
Protection against impacts: IK 04

■ 5.2 Material characteristics

Front plate, rocker: ABS
Mechanism, support : PC
Claws: steel

UV-resistant
Halogen-free

Self-extinguishing:

850°C/30 s for insulating components holding live parts in place.
650°C/30 s for other insulating components.

■ 5.3 Electrical characteristics

Voltage: 250 V~
Current: 20 A
Frequency: 50/60 Hz

■ 5.4 Climate characteristics

Storage temperature: - 10° C to + 70° C
Use temperature: - 5° C to + 40° C

6. CLEANING

Surface cleaning with a cloth.

Do not use: acetone, tar remover, trichloroethylene.

Maintenance with the following products: Hexane, Methylated spirit, Soapy water, Diluted ammonia, Bleach diluted to 10%, Window-cleaning products, Pre-saturated wipes.

Caution: A preliminary test should be carried out if other specific cleaning products are to be used.

7. STANDARDS AND APPROVALS

Compliance with standards of installation and manufacturing.
Refer to e.catalogue.