
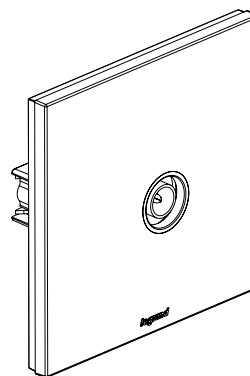


Urbano™
Prise TV type F - Prise TV simple male

**Cat. No(s): UB2410GR/WH - UB2411GR/WH
 UB2412GR/WH - UB2413GR/WH**

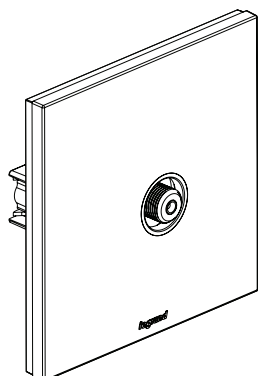


1. USE

TV connector mechanisms
 The mechanisms are supplied with rocker, supports and plates.
 Equipped with single-post plates.
 Flush mounting mechanisms
 Fixing with claws and/or screws.

2. RANGE

| Description | White | Grey |
|---------------------------|----------|----------|
| Single star TV socket | UB2410WH | UB2410GR |
| F type star TV socket | UB2411WH | UB2411GR |
| Single pass TV socket | UB2412WH | UB2412GR |
| Single terminal TV socket | UB2413WH | UB2413GR |

3. OVERALL DIMENSIONS (mm)

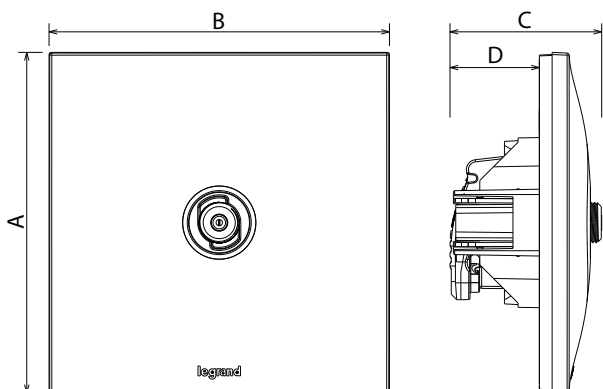

| References | A | B | C | D |
|---|----|----|-------|----|
| UB2410GR/WH - UB2412GR/WH - UB2413GR/WH | 80 | 80 | 33 | 21 |
| UB2411GR/WH | 80 | 80 | 35.65 | 21 |

4. TECHNICAL CHARACTERISTICS

- **4.1 Protection index**
 Protection against solid bodies and liquids: IP20
 Protection against impacts: IK 04
 Cable tensile strength 120 N: standard IEC 61169-24
- **4.2 Material characteristics**
 Plate : ABS
 Mechanism : Zamac
 Support : PC
 Claws: steel
 UV-resistant
 Halogen-free
- **4.3 Electrical characteristics**
 - Characteristic impedance: 75 ohm
 - Male connector Ø 9.52 mm
 - Type F female connector to screw
 - Class A shielding effectiveness
 - Frequency bands: TV/SAT: 0 - 2400 MHz
 - Attenuation: 1 dB maximum
 - Insulation resistance: IEC 61169-24 standard
 - Compatible with remote power supply
- **4.4 Climate characteristics**
 Storage temperature: - 10° C to + 70° C
 Use temperature: - 5° C to + 40° C

5. CLEANING

Surface cleaning with a cloth.
 Do not use: acetone, tar remover, trichloroethylene.
 Maintenance with the following products: Hexane, Methylated spirit, Soapy water, Diluted ammonia, Bleach diluted to 10%, Window-cleaning products, Pre-saturated wipes.

Caution: A preliminary test should be carried out if other specific cleaning products are to be used.

6. STANDARDS AND APPROVALS

Compliance with standards of installation and manufacturing.
 Refer to e.catalogue.