
 



Tower

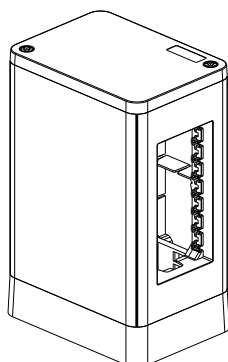


653200



653201

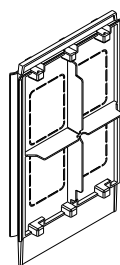

653202

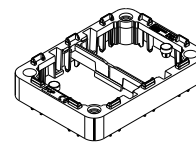

653203

Use

 
Tower 4 modules for surface mounting installation.
Can be extended to 8,16 or more modules thanks to the accessories (additional support and joining kits)
Compatible with our 45x45 format wiring devices (Mosaic, Arteor, Matix Go, Lyncus)

Range

Designation

Item

Turret - white case




☐ 653200

Color code:

☐ White (RAL 9003) and grey.

Overall dimensions (mm)

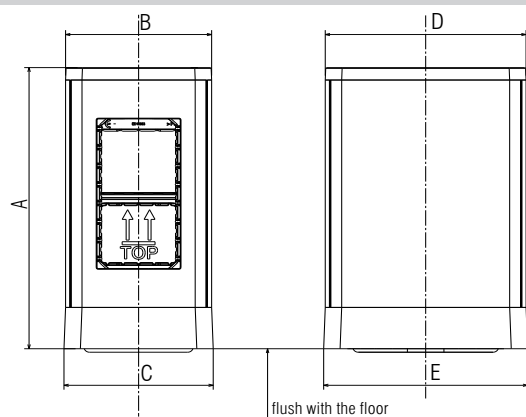

	A	B	C	D	E
653200	170	80	82	110	112

Accessory

Supporting frame 4m



☐ 653201

 
Accessory

Horizontal junction



653202

Vertical junction



653203

Color code: ☐ White (RAL 9003)

Technical characteristics

- Protection index

(considering a complete installation Penetration by solid bodies/liquid: IP40

- The mini-columns have been fitted with an IP 52 sealing gasket located under the base, preventing any penetration of dust or liquid between the floor and the base.

- Mechanical characteristics

Impact test: IK 08

- Material characteristics

Materials:

- White covers: ABS
- Internal structure: PA6 with fiber glass
- Grey covers: PC (polycarbonate)
- Yellow separator: PP (polypropylene)

UV resistant. Halogen free.

Self-extinguishing:

650° C / 30 s for parts made of insulating materials

- Climatic characteristics

Storage temperature: - 10° C to + 70° C

Use temperature: - 5° C to + 35° C

Cleaning

Clean the surface with a cloth.

Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Caution: Always test before using special cleaning products.

Standards and approvals

Compliance with standards CEI EN 50085-2-4

Refer to e.catalogue.