


Urbano™
Phone T socket

Cat. No(s): UB4210GR/WH

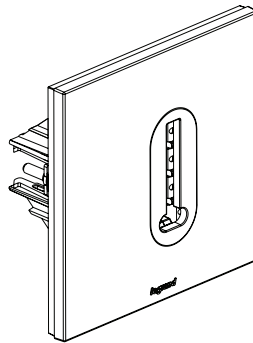


1. USE

Connector mechanisms for telephone sockets.
 The mechanisms are supplied with rocker, supports and plates.
 Equipped with single-post plates.
 Flush mounting mechanisms
 Fixing with claws and/or screws.

2. RANGE

Description	White	Grey
Phone T socket	UB4210WH	UB4210GR

3. OVERALL DIMENSIONS (mm)

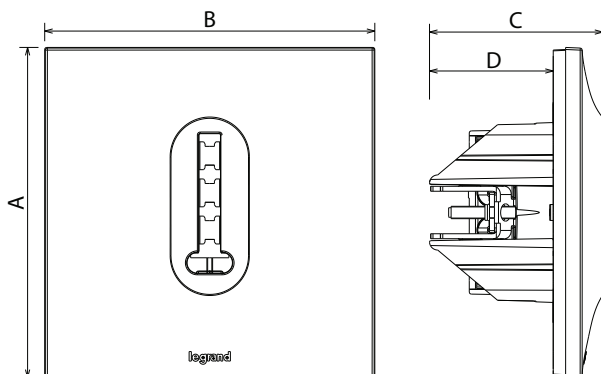

References	A	B	C	D
UB2410GR/WH	80	80	44	30

4. TECHNICAL CHARACTERISTICS

■ **4.1 Protection index**

Protection against solid bodies and liquids: IP20
 Protection against impacts: IK 04

■ **4.2 Material characteristics**

Front plate : ABS
 Mechanism, support : PC
 Claws: steel
 UV-resistant
 Halogen-free

■ **4.3 Electrical characteristics**

For safety reasons, the combination in the same box of a telephone socket and an electrical socket is prohibited.

■ **4.4 Climate characteristics**

Storage temperature: - 10° C to + 70° C
 Use temperature: - 5° C to + 40° C

5. CLEANING

Surface cleaning with a cloth.
 Do not use: acetone, tar remover, trichloroethylene.

Maintenance with the following products: Hexane, Methylated spirit, Soapy water, Diluted ammonia, Bleach diluted to 10%, Window-cleaning products, Pre-saturated wipes.

Caution: A preliminary test should be carried out if other specific cleaning products are to be used.

6. STANDARDS AND APPROVALS

Compliance with standards of installation and manufacturing.
 Refer to e.catalogue.