
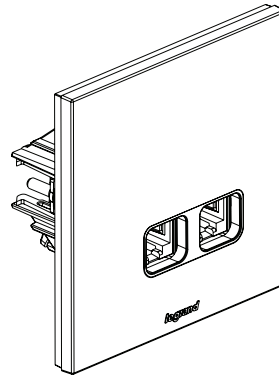


**Urbano™**  
**RJ45 socket Cat. 6**

Cat. No(s): UB4311GR/WH - UB4312GR/WH - UB4321GR/WH

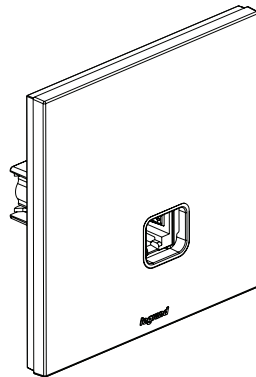


**1. USE**

Single or twin RJ45 connector mechanisms.  
 The mechanisms are supplied with rocker, supports and plates.  
 Equipped with single-post plates.  
 Flush mounting mechanisms  
 Fixing with claws and/or screws.

**2. RANGE**

| Description                 | White    | Grey     |
|-----------------------------|----------|----------|
| RJ45 socket Cat. 6 UTP      | UB4311WH | UB4311GR |
| RJ45 socket Cat. 6 FTP      | UB4312WH | UB4312GR |
| Dual RJ45 socket Cat. 6 UTP | UB4321WH | UB4321GR |

**3. OVERALL DIMENSIONS (mm)**

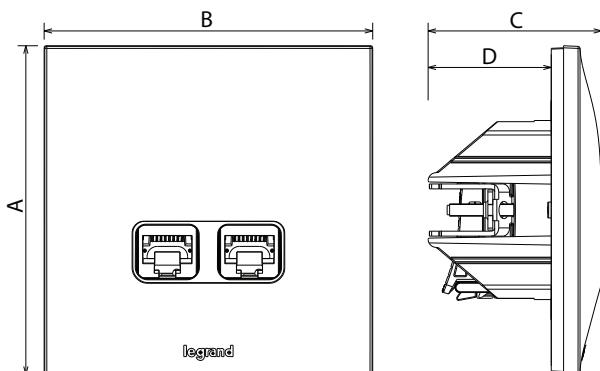

| References  | A  | B  | C     | D    |
|-------------|----|----|-------|------|
| UB4311GR/WH | 80 | 80 | 38.9  | 26.6 |
| UB4312GR/WH | 80 | 80 | 38.9  | 26.6 |
| UB4321GR/WH | 80 | 80 | 42.25 | 30   |

**4. TECHNICAL CHARACTERISTICS**

- **4.1 Protection index**  
 Protection against solid bodies and liquids: IP20  
 Protection against impacts: IK 04
- **4.2 Material characteristics**  
 Front plate : ABS  
 Mechanism, support : PC  
 Claws: steel  
 UV-resistant  
 Halogen-free
- **4.3 Electrical characteristics**  
 Equipped with a quick connection connector.
- **4.4 Climate characteristics**  
 Storage temperature: - 10° C to + 70° C  
 Use temperature: - 5° C to + 40° C

**5. CLEANING**

Surface cleaning with a cloth.  
 Do not use: acetone, tar remover, trichloroethylene.  
 Maintenance with the following products: Hexane, Methylated spirit, Soapy water, Diluted ammonia, Bleach diluted to 10%, Window-cleaning products, Pre-saturated wipes.

**Caution:** A preliminary test should be carried out if other specific cleaning products are to be used.

**6. STANDARDS AND APPROVALS**

Compliance with standards of installation and manufacturing.  
 Refer to e.catalogue.