


Céliane™

Dimmer for ceiling fans speed control

Cat. No(s): CM0015

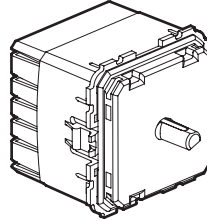


1. USE

Controls and varies the speed of a ceiling fan.
 Surface or recessed installation in a box at least 40 mm deep.

2. RANGE

	Cat. No.
Fan control with fan speed variation function. To be combined with cover, support and finishing plate. 2 modules.	CM0015

3. DIMENSIONS (mm)

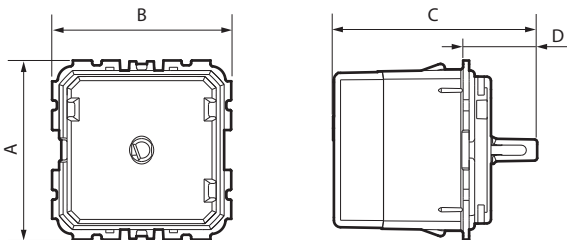


A	B	C	D
45	45	51	18.5

4. CONNECTION

Type of terminals: with screws
 Terminal capacity: 1 x 2.5 mm² or 2 x 1.5 mm²
 Longueur de dénudage : 8 mm
 Tournevis : 3,5 mm

5. FONCTIONNEMENT

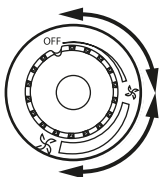

Dimming of fan speed by turning the knob

6. TECHNICAL CHARACTERISTICS

■ 6.1 Mechanical characteristics

Protection against impacts: IK 04
 Protection against solid bodies and liquids: IP 20

■ 6.2 Material characteristics

Mechanism casing: PC
 Cover: PC

Halogen-free

Self-extinguishing:

850°C/30 s for insulating components holding live parts in place.
 650°C/30 s for other insulating components.

■ 6.3 Electrical characteristics

Voltage: 230 V~

Power: 400 VA max.

40 VA min.

Frequency: 50/60 Hz

■ 6.4 Climate characteristics

Usage temperature: + 5°C to + 45°C

Storage temperature: 0°C to + 45°C

7. CARE

Clean the surface with a cloth.

Do not use acetone, tar-removing cleaning agents or trichloroethylene.

8. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.

See e.catalogue.