


Céliane™ with Netatmo

Connected control switch for color ambiances

Cat. No(s): CB2419 - CN2419 - CT2419

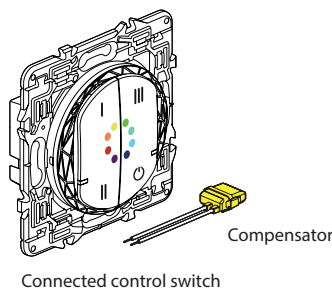

1. USE


Wired color dimming controller to control connected multicolor, neutral-free 125 W LED lighting with dimmer option, default ON/OFF (dimming mode can be activated from Home + Control App).
Can be combined with one or more wireless lighting controllers for local or remote control of your lighting.
Supplied with an active compensator (Cat. No 0 401 49), mandatory for optimum operation with market lamps. Only one compensator per lighting circuit.
With LED (configuration) and RESET button (hidden) to return to factory mode.
Easily installed in place of a standard switch in a box at least 40 mm deep.

2. RANGE

Wired control (without neutral) for color dimming.
3 moods to choose from (I - II - III), set in the Home + Control App.

White	Black	Titanium
CB2419	CN2419	CT2419

3. DIMENSIONS (mm)

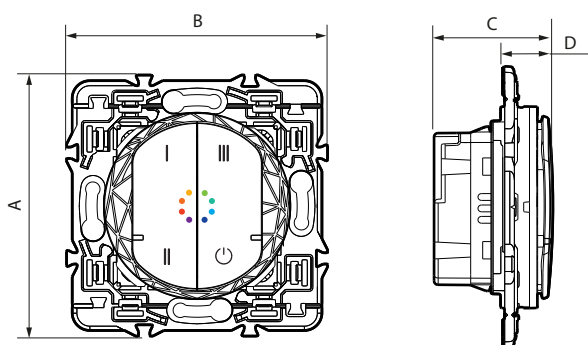


A	B	C	D
74	74	31	13

4. CONNECTION

Type of terminals: screws
Terminal capacity: 2 x 1,5 mm² maximum or 1 x 2,5 mm²
Stripping length: 8 mm
Flat-blade screwdriver: 3 mm

5. OPERATION

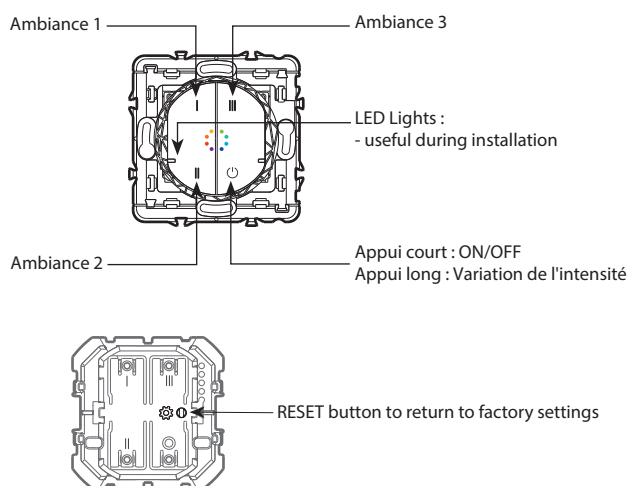

6. TECHNICAL CHARACTERISTICS

6.1 Mechanical characteristics

Protection against impacts: IK 04
Protection against solid bodies and/or liquids: IP 20

6.2 Material characteristics

Grid: PA 6,6 + Galfan steel
Mechanism casing: PC
Rocker plate: ABS

Halogen-free
UV-resistant

Self-extinguishing:
850°C/30 s for insulating components holding live parts in place.
650°C/30 s for other insulating components.

6. TECHNICAL CHARACTERISTICS *(continued)*

■ 6.3 Electrical characteristics

Voltage: 240 V~

Power: 125 W

Frequency: 50 Hz

Standby consumption: 1,5 mA

■ Zigbee radio technology

Fréquency: 2,4 GHz to 2,4835 GHz

Power level: < 100 mW

Range: 200 m in open field

10 m are recommended between indoor products

■ 6.4 Climate characteristics

Usage temperature: +5°C to +35°C

Storage temperature: 0°C to +45°C

7. CARE

Clean the surface with a cloth.

Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Resistant to the following products:

Hexane, methylated spirit, soapy water, diluted ammonia, bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

Caution: Always test before using special cleaning products.

8. STANDARDS AND APPROVALS

The undersigned, LEGRAND, declares that the radio-electric equipment type (CB2419 - CN2419 - CT2419) complies with directive 2014/53/EU.

The full text of the EU declaration of conformity is available on the following website: www.legrand.com/ecatalogue