



Arteor™ Advance with Netatmo Smart roller shutter and curtains switch

Cat. Nos: AC5310MW/MB/MT
AA5310MW/MB/MT

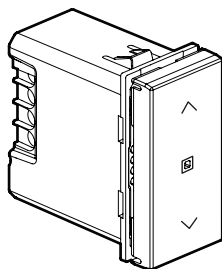

AC5310MW/MB/MT

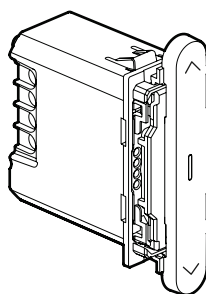

AA5310MW/MB/MT

1. USE

For local or remote control of your roller shutters and curtains. Requires the prior installation of a smart Gateway "with Netatmo". Can be combined with one or more smart curtain/roller shutter wireless control.

The Arteor with Netatmo solution is compatible with roller shutters with a mechanical or electronical stop, controlled by a standard wired switch for roller shutters.


Can be installed in place of an existing roller shutter switch in a flush-mounting box 40 mm deep minimum.

Caution: Must be connected to the neutral. Not compatible with radio-controlled roller shutter motors. To be equipped with a frame and plate.

2. RANGE

Designation	Finishes		
	Matt White	Matt Black	Matt Titanium
Smart roller shutter blind and curtain switch	AC5310MW	AC5310MB	AC5310MT
	AA5310MW	AA5310MB	AA5310MT

3. DIMENSIONS (mm)

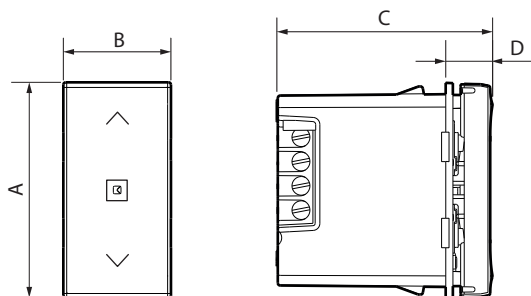

Cat. Nos	A	B	C	D
AC5310MW/MB/MT	45	22.5	44	9
AA5310MW/MB/MT	60	22.5	44	9

4. CONNECTION

Terminal type: with screws


Terminal capacity: 1 x 2.5 mm² - 2 x 1.5 mm²

Stripping length: 7 mm

Screwdriver: 3 mm flat

5. OPERATION

Integrated time delay for up/down inversion: 500 ms

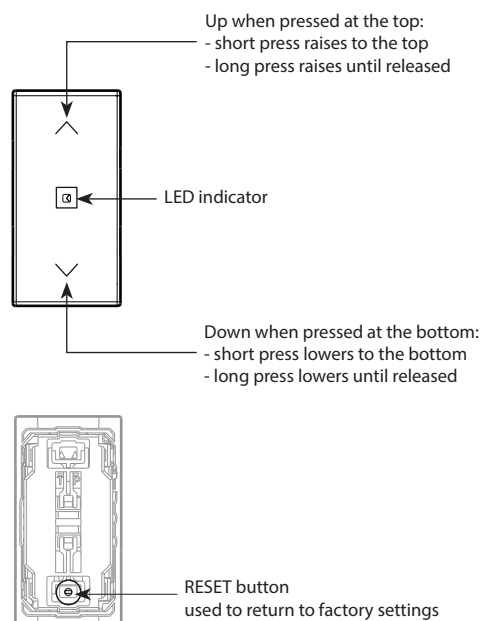

6. TECHNICAL CHARACTERISTICS

■ 6.1 Mechanical characteristics

Protection against impacts: IK 04

Protection against solid bodies/liquids: IP 20

■ 6.2 Material characteristics

Mechanism casing: PC

Rocker: PC or ABS

Halogen-free

UV-resistant

Self-extinguishing:

850°C/30 s for insulating components holding live parts in place.

650°C/30 s for other insulating components.

■ 6.3 Electrical characteristics

Voltage: 110/230 V~

Current: 2 A

Max. switching power: 500 W

Standby consumption: 2.1 mA

Zigbee technology

Frequency bands: 2.4 GHz to 2.4835 GHz

Power level: < 100 mW

Range: 200 m of unobstructed space

■ 6.4 Climate characteristics

Storage temperature: 0°C to +45°C

Usage temperature: +5°C to +35°C

7. CLEANING

Clean the surface with a cloth.

Do not use acetone, tar-removing cleaning agents or trichloroethylene.

Resistant to the following products: Hexane, methylated spirit, soapy water, diluted ammonia, bleach diluted to 10%, window-cleaning products, pre-impregnated wipes.

Resistant to hospital grade cleaning products:

Anios, surfanios, bactilysine, diluted hydrogen peroxide (35%).

Caution: Always test before using special cleaning products.

8. STANDARDS AND APPROVALS

The undersigned, LEGRAND, declares that the radio-electric equipment type smart product "with Netatmo" complies with directive 2014/53/EU.