


**SUNO™ - SEANO™**

**Wireless remote master switch home/ away repeater**

**Cat. No(s): 7 221 76 - 7 222 76 - 7 223 76 - 7 224 76  
 7 656 36 - 7 657 36 - 7 658 36 - 7 659 36**

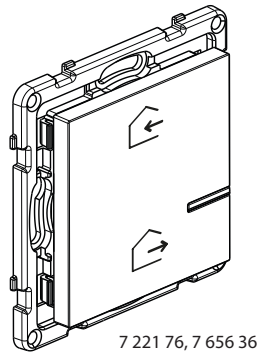

7 221 76, 7 656 36


**1. USE**

A wireless general control, used to control leaving home/coming home scenes involving lights, roller shutters and connected sockets. Fixes directly on the wall or screws onto a flush-mounting box. Multi-gang versions can be combined with other wiring accessories. Fits on a piece of furniture (movable).

**2. RANGE**


Description:	Family	White	Ivory	Aluminum	Black	Dark Grey
Wireless remote master switch home/ away repeater	SUNO	7 221 76	7 222 76	7 223 76	7 224 76	-
	SEANO	7 656 36	-	7 657 36	7 658 36	7 659 36

**3. DIMENSIONS (mm)**

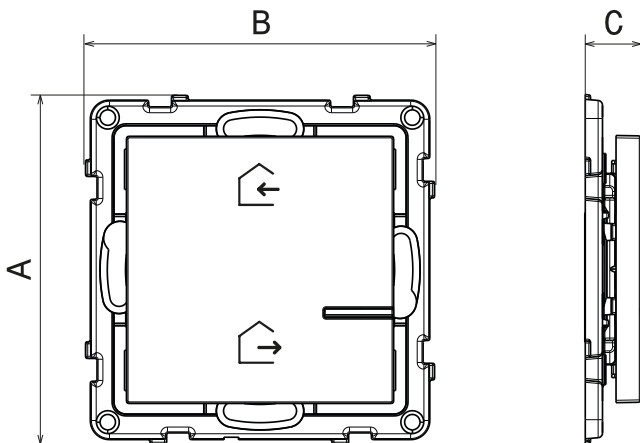

References	A	B	C
722176, 7 656 36	72.9	72.9	11.5

**4. OPERATION**

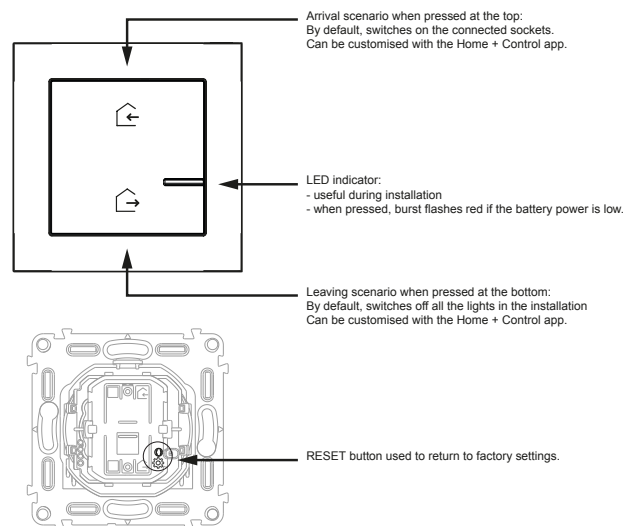

**5. TECHNICAL CHARACTERISTICS**

- **5.1 Mechanical characteristics**
- Protection against impacts: IK 02
- Protection against solid bodies and/or liquids: IP 20 without rocker plate and plate  
 IP 40 for assembled product

## Wireless remote master switch home/ away repeater

### ■ 5.2 Material characteristics

Rocker: ABS

Support: Mechanism casing with grid: Fibreglass-reinforced (10 %) PC

Colours: White RAL 9003

Ivory RAL 1013

Painted Aluminium, Black, Dark Grey

Halogen-free

UV resistant

Self-extinguishing:

850° C / 30 s for insulating parts holding live parts in place.

650° C / 30 s for the other insulating components.

### ■ 5.3 Material characteristics of general control

Powered by a CR2032 - 3 V lithium battery (supplied)

Battery life: 8 years for 10 activations a day

ZigBee radio technology frequency: 2.4 GHz to 2.4835 GHz

Wireless mesh network, self-adaptive and secure (AES 128), conforming to standard IEEE 802.15.4 (LR-WPAN)

Power level: REC 70-03 < 20 dBm

### ■ 5.4 Climate characteristics

Storage temperature: 0° C to + 45° C

Usage temperature: + 5° C to + 45° C

## 6. MAINTENANCE

Clean the surface with a cloth. Do not use acetone, tar-removing cleaning agents or trichloroethylene. Resistant to the following products:

Hexane (EN 60669-1),

methylated spirit, soapy water, diluted ammonia, bleach diluted to

10%, window-cleaning products, pre-impregnated wipes. The plates

must not be painted.

Caution: Always test before using special cleaning products.

Do not paint the cover plate!



Take care to recycle the battery appropriately.

## 7. ACCESSORIES

0 648 71: Repositionable adhesive for wireless control (x 4 supplied)

## 8. STANDARDS AND APPROVALS

Compliant with installation and manufacturing standards.

See e-catalogue.

The undersigned, LEGRAND, declares that the radio-electric equipment

type (Cat. Nos 7 221 76 - 7 222 76 - 7 223 76 - 7 224 76 - 7 656 36 - 7 657

36 - 7 658 36 - 7 659 36) complies with directive 2014/53/EU. The full

text of the EU declaration of conformity is available on the following

website: [www.legrand.com/ecatalogue](http://www.legrand.com/ecatalogue)