



Obria™ BS 15A Socket

Cat. No(s): MEC32042XX MY MEC31043 MY
 "XX" = Color / finishes: WH SL CH BL RG
 "MY" = Malaysia

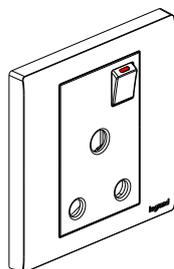

MEC32042XX MY

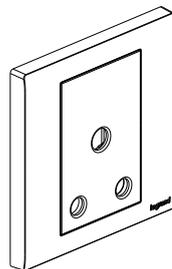

MEC31043XX MY

1. USE

15A socket outlets designed to accept BS 15A plugs.
 (Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.)

2. RANGE


Designation	Cat. No.
1G BS 15A SWITCHED SOCKET	MEC32042XX MY
1G BS 15A UNSWITCHED SOCKET	MEC31043XX MY

Colours

-Matt colors finishes

WH: Matt White
 SL: Dark silver
 CH: Champagne
 BL: Matt Black
 RG: Rose gold

3. DIMENSIONS (mm)

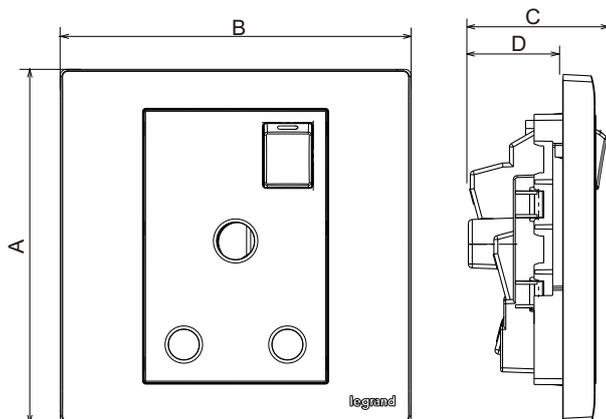

References	A	B	C	D
MEC32042XX MY	87.4	86	34.3	23.5
MEC31043XX MY	87.4	86	31.6	23.5

Box depth ≥ 35 mm

4. CONNECTION

Types of terminals: with screws
 Terminal capacity: 3 × 2.5 mm²
 2 × 4 mm²
 1 × 6 mm²

Recommended stripping length: 12 mm
 Recommended screwdriver size: <4 mm flat blade

5. TECHNICAL CHARACTERISTICS

5.1 Material characteristics

Plate: PC
 Rocker: PC
 Frame: PC
 Base: PC
 Self-extinguishing:
 + 850° C / 30 s for insulating parts holding live parts in place
 + 650° C / 30 s for other parts made of insulating materials

5.2 Electrical characteristics

Voltage: 250V~
 Current: 15A

5.3 Climatic characteristics

Storage temperatures: -10°C to +70°C
 Operating temperatures: -5°C to +35°C

5.4 Mechanical characteristics

Impact test: IK04
 Protection against solids & liquids: IP20

6. CLEANING

Surface cleaning with a soft, slightly damp cloth.
 Do not use: acetone, tar remover, trichloroethylene

7. CONFORMITY - APPROVALS

Conform to BS 546.