


Obria™ 400W Rotary dimmer

Cat. No(s): MEC24012XX MY
 "XX" = Color / finishes: WH SL CH BL RG
 "MY" = Malaysia

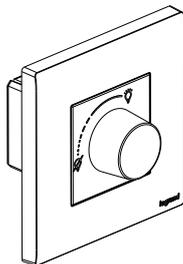

MEC24012XX MY

1. USE

Light control.
 (Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.)

2. RANGE


Designation	Cat. No.
1G 60-400W INCANDESCENT DIMMER 230V	MEC24012XX MY

Colours

-Matt colors finishes

WH: Matt White
 SL: Dark silver
 CH: Champagne
 BL: Matt Black
 RG: Rose gold

3. DIMENSIONS (mm)

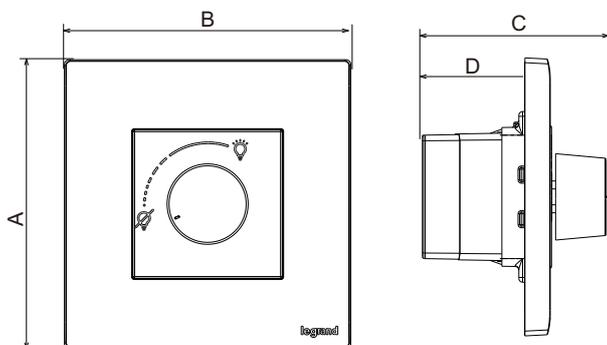

References	A	B	C	D
MEC24012XX MY	87.4	86	57.3	31.9

Minimum depth of the box > 35 mm

4. CONNECTION

4.1 Terminal

Types of terminals: with screws
 Terminal capacity: 4 × 1 mm²
 3 × 1.5 mm²
 2 × 2.5 mm²
 1 × 4 mm²

Recommended stripping length: 8 mm
 Recommended screwdriver size: 4 mm flat blade

5. TECHNICAL CHARACTERISTICS

5.1 Material characteristics

Button: PC
 Plate: PC
 Frame: PC
 Base: PC
 Self-extinguishing:
 + 850°C / 30 s for insulating parts holding live parts in place
 + 650°C / 30 s for other parts made of insulating materials

5.2 Electrical characteristics

Voltage: 220 - 240V~
 Frequency: 50/60Hz

	R	
Max	400W	
Min	60W	

5.3 Climatic characteristics

Storage temperatures: -10°C to +70°C
 Operating temperatures: -5°C to +35°C

5.4 Mechanical characteristics

Impact test: IK04
 Protection against solids & liquids: IP20

6. CLEANING

Surface cleaning with a soft, slightly damp cloth.
 Do not use: acetone, tar remover, trichloroethylene.

7. CONFORMITY - APPROVALS

Conform to IEC 60669-2-1, BS EN 60669-2-1.