


# Obria™ Shaver socket

Cat. No(s): MEC36019/74XX MY  
 "XX" = Color / finishes: WH SL CH BL RG  
 "MY" = Malaysia

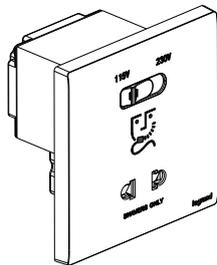

MEC36019XX MY



MEC36074XX MY

## 1. USE

Device for the supply of electric shavers requiring either a 230V or 120V supply and having a power consumption not exceeding 20VA. Accepts the following types of plug: BS, Euro, US, Australian and Chinese.  
 (Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.)

## 2. RANGE


Designation	Cat. No.
SHAVER SOCKET	MEC36019XX MY
2 GANG SHAVER SOCKET	MEC36074XX MY

## Colours

-Matt colors finishes

WH: Matt White  
 SL: Dark silver  
 CH: Champagne  
 BL: Matt Black  
 RG: Rose gold

## 3. DIMENSIONS (mm)

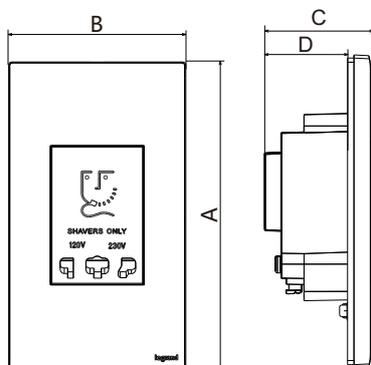

References	A	B	C	D
MEC36019XX MY	87.4	86	58.7	49.7
MEC36074XX MY	150	86	51	43

Minimum depth of the box > 48 mm

## 4. CONNECTION

Types of terminals: auto terminal  
 Terminal capacity: 2 X 1.5 mm<sup>2</sup>  
 2 X 2.5 mm<sup>2</sup>  
 Recommended stripping length: 13 mm

## 5. TECHNICAL CHARACTERISTICS

### 5.1 Material characteristics

Plate: PC  
 Frame: PC  
 Base: PC  
 Self-extinguishing:  
 + 850° C / 30 s for insulating parts holding live parts in place  
 + 650° C / 30 s for other parts made of insulating materials

### 5.2 Electrical characteristics

MEC36019XX MY  
 Transformer: primary and secondary 230 V - 115/230 V  
 Frequency: 50/60 Hz  
 Power: 20VA Max.

MEC36074XX MY  
 Transformer: primary and secondary 230 V - 120/230 V  
 Frequency: 50/60 Hz  
 Power: 20VA Max.

### 5.3 Climatic characteristics

Storage temperatures: -10°C to +70°C  
 Operating temperatures: -5°C to +35°C

### 5.4 Mechanical characteristics

Impact test: IK04  
 Protection against solids & liquids: IP24

## 6. CLEANING

Surface cleaning with a soft, slightly damp cloth.  
 Do not use: acetone, tar remover, trichloroethylene

## 7. CONFORMITY - APPROVALS

Conform to BS EN 61558-2-5.