



Obria™ 16A Multistandard socket

Cat. No(s): MEC32045/46XX MY
 "XX" = Color / finishes: WH SL CH BL RG
 "MY" = Malaysia

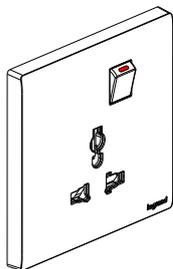

MEC32045XX MY

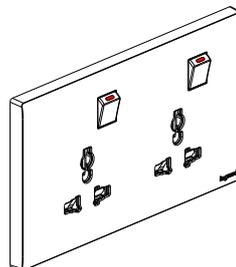

MEC32046XX MY

1. USE

One and two gang switched multistandard socket.
 (Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.)

2. RANGE


Designation	Cat. No.
1G 16A MULTISTANDARD SWITCHED SOCKET	MEC32045XX MY
2G 16A MULTISTANDARD SWITCHED SOCKET	MEC32046XX MY

Colours

-Matt colors finishes

WH: Matt White
 SL: Dark silver
 CH: Champagne
 BL: Matt Black
 RG: Rose gold

3. DIMENSIONS (mm)

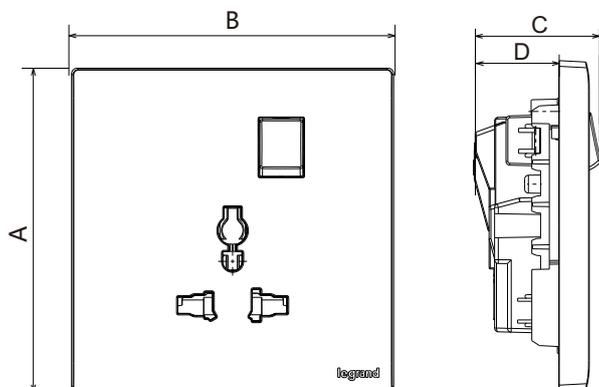

References	A	B	C	D
MEC32045XX MY	87.4	86	33.2	22.2
MEC32046XX MY	87.4	146	33.2	22.2

Recommended box depth ≥ 35 mm

4. CONNECTION

Types of terminals: with screws
 Terminal capacity: 3 × 1 mm²
 3 × 1.5 mm²
 2 × 2.5 mm²
 1 × 4 mm²

Recommended stripping length: 12 mm
 Recommended screwdriver size: <4 mm flat blade

5. TECHNICAL CHARACTERISTICS

5.1 Material characteristics

Rocker: PC
 Plate: PC
 Frame: PC
 Base: PC
 Self-extinguishing:
 + 850° C / 30 s for insulating parts holding live parts in place
 + 650° C / 30 s for other parts made of insulating materials

5.2 Electrical characteristics

Multistandard Socket:
 Voltage: 250V~ Current: 16A
 Frequency: 50/60Hz

5.3 Climatic characteristics

Storage temperatures: -10°C to +70°C
 Operating temperatures: -5°C to +35°C

5.4 Mechanical characteristics

Impact test: IK04
 Protection against solids & liquids: IP20

6. CLEANING

Surface cleaning with a soft, slightly damp cloth.
 Do not use: acetone, tar remover, trichloroethylene

7. CONFORMITY - APPROVALS

Conform with installation and manufacturing standards.
 Refer to e-catalogue.