


Obria™ 32A DP Switch

Cat. No(s): MEC21027XX MY
 "XX" = Color / finishes: WH SL CH BL RG
 "MY" = Malaysia

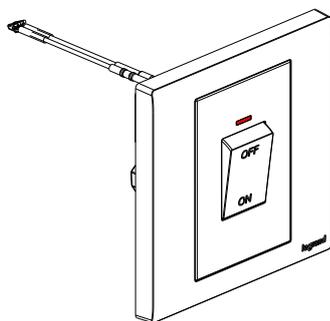

MEC21027XX MY

1. USE

High capacity double pole switches for the control of fixed appliances eg. cooker ovens, shower or air-conditioning units.
 (Supplied with M3.5 screws for Flush mounting or surface mounting BS boxes.)

2. RANGE


Designation	Cat. No.
1G 1W 32A DP SWITCH RED LED INDICATOR	MEC21027XX MY

Colours

-Matt colors finishes

WH: Matt White
 SL: Dark silver
 CH: Champagne
 BL: Matt Black
 RG: Rose gold

3. DIMENSIONS (mm)

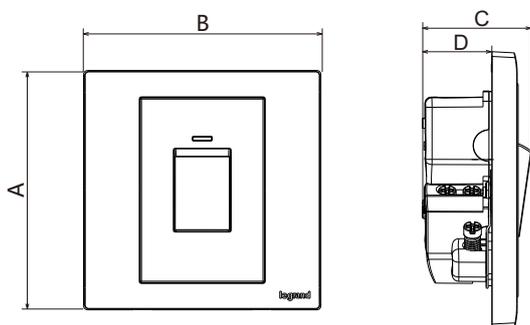

References	A	B	C	D
MEC21027XX MY	87.4	86	33.9	21.8

Box depth ≥ 40 mm

4. CONNECTION

Types of terminals: with screws
 Terminal capacity: 2 × 6 mm²
 1 × 10 mm²
 Recommended stripping length: 24 mm
 Recommended screwdriver size: <4 mm flat blade

5. TECHNICAL CHARACTERISTICS

5.1 Material characteristics

Rocker: PC
 Plate: PC
 Frame: PC
 Base: PC
 Self-extinguishing:
 + 850° C / 30 s for insulating parts holding live parts in place
 + 650° C / 30 s for other parts made of insulating materials

5.2 Electrical characteristics

Voltage: 250V~
 Current: 32A

5.3 Climatic characteristics

Storage temperatures: -10°C to +70°C
 Operating temperatures: -5°C to +35°C

5.4 Mechanical characteristics

Impact test: IK04
 Protection against solids & liquids: IP20

6. CLEANING

Surface cleaning with a soft, slightly damp cloth.
 Do not use: acetone, tar remover, trichloroethylene

7. CONFORMITY - APPROVALS

Conform to IEC 60669-1.